


# Horizontal Rail, Front, Type L-KD, Light, Short Lip, 28 HP

## KATALOGOVÉ ČÍSLO

**34560-128**

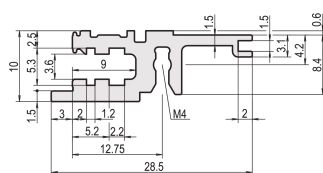

Combinations of horizontal rails and side panels

|                                                            | Standard rail | Standard rail with short lip | Standard rail with short lip and side panel | Standard rail with short lip and side panel with short lip |
|------------------------------------------------------------|---------------|------------------------------|---------------------------------------------|------------------------------------------------------------|
| Standard rail                                              | -             | +                            | +                                           | +                                                          |
| Standard rail with short lip                               | +             | +                            | +                                           | +                                                          |
| Standard rail with short lip and side panel                | +             | +                            | -                                           | -                                                          |
| Standard rail with short lip and side panel with short lip | +             | +                            | -                                           | -                                                          |

Legend: + can be combined, - combination not recommended

The horizontal rail with a short lip makes a clean design to the assembled front panel.

## CERTIFICATIONS



## VLASTNOSTI

Standard rail at the front

Installation at top and bottom

Short lip (L-KD)

< 28 HP not to print

Aluminum extrusion, anodized finish, conductive contact surface

## VLASTNOSTI PRODUKTU

Rack Width: 28HP

Množství v balení: 1

Povrchová úprava: Anodized

Length: 147.32mm

Materiál: Hliník

Produktová řada: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Product Type: Horizontal Rail

Typ: Light, KD

Works With: Subracks; Cases

## DALŠÍ PODROBNOSTI O PRODUKTU

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na [www.nvent.com](http://www.nvent.com) a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE