


# Horizontal Rail, Front, Type R-LD, Rugged, Long Lip , 28 HP

KATALOGOVÉ ČÍSLO

**34566-328**

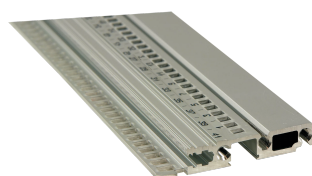

### Combinations of horizontal rails and side panels

 = can be combined, 
  = combination not recommended

|            | Recessed A                                                                        |                                                                                   | Recessed B                                                                        | Recessed C                                                                        | Recessed D                                                                        | Recessed E                                                                        |
|------------|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|
| Recessed A |  | -                                                                                 |  |  |  |  |
| Recessed B |  |  | recessed B1 (fixed on the connector)                                              | recessed B with frame and connector                                               | recessed B with frame and connector                                               | +                                                                                 |
| Recessed C |  | +                                                                                 | recessed C1 (fixed)                                                               | recessed C1 (fixed)                                                               | recessed C with frame and connector                                               | +                                                                                 |
| Recessed D |  | +                                                                                 | recessed D1 (fixed)                                                               | recessed D1 (fixed)                                                               | -                                                                                 | -                                                                                 |
| Recessed E |  | -                                                                                 | -                                                                                 | -                                                                                 | -                                                                                 | -                                                                                 |
| Side panel |  | 1000 x 1                                                                          | Recessed B                                                                        | Recessed C                                                                        | Recessed D                                                                        | Recessed E                                                                        |

The rugged horizontal rail type can handle shock and vibration up to 25 g. It enables the use of IEEE handles.

## CERTIFICATIONS



## VLASTNOSTI

Type R-LD "rugged" horizontal rails with 3-hole fixing for increased robustness

For insertion/extraction of CompactPCI or, VME64x boards

With HP units printed from 28 HP upwards

Length 20, 28, 40, 42, 63, 84 HP or 1000 mm

Aluminum extrusion, anodized finish, conductive contact surface, with HP markings

## VLASTNOSTI PRODUKTU

Rack Width: 28HP

Množství v balení: 1

Povrchová úprava: Anodized

Length: 147.32mm

Materiál: Hliník

Produktová řada: EuropacPRO

Product Type: Horizontal Rail

Typ: Rugged, LD

Works With: Subracks

Net Weight: 0.09kg

## UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na [www.nvent.com](http://www.nvent.com) a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE