
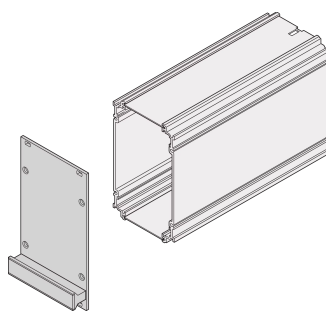


Frame Type Plug-In Unit Front Panel, Unshielded, 6 U, 12 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

KATALOGOVÉ ČÍSLO

34812-612

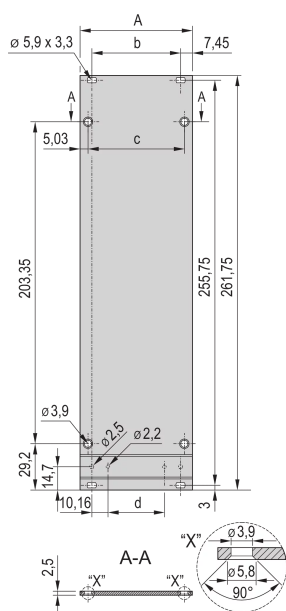

Front Panel for frame type plug-in unit, shieldable.

CERTIFICATIONS



VLASTNOSTI

Al, 2.5 mm, front anodized, rear anodized, cut edges blank

Front Panel for frame type plug-in units PRO

VLASTNOSTI PRODUKTU

Rack Width: 12HP

Accessory Type: Front panel

Množství v balení: 1

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Hloubka (D): 2.5mm

Povrchová úprava: Anodized

Výška (H): 261.75mm

Materiál: Hliník

Product Type: Front Panel

Rack Height: 6U

Šířka (W): 60.62mm


Net Weight: 0.1kg

DALŠÍ PODROBNOSTI O PRODUKTU

Mounting kit to fix front Panel to plug-in unit, handle to bolt on, clip and screw with plastic sleeve for mounting plug-in unit in subrack or case are included in the item 'Mounting kit for five plug-in units', part number 24812-100. The handle is available in 2 colors (grey or black). Individual parts 100 pieces. Screw for fixing front Panel to plug-in unit, part no. 24812-501. Screw for mounting handle, part no. 24560-179 Clip - mounting aid for handle, part no. 21101-239. Screw for sleeve, threaded insert front inserted into horizontal rail, part no. 21100-748. Screw for sleeve, threaded insert rear inserted into horizontal rail, part no. 21101-101. Sleeve 21100-660, 21100-661, 21100 - 662, 21100-886, 21100-146.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

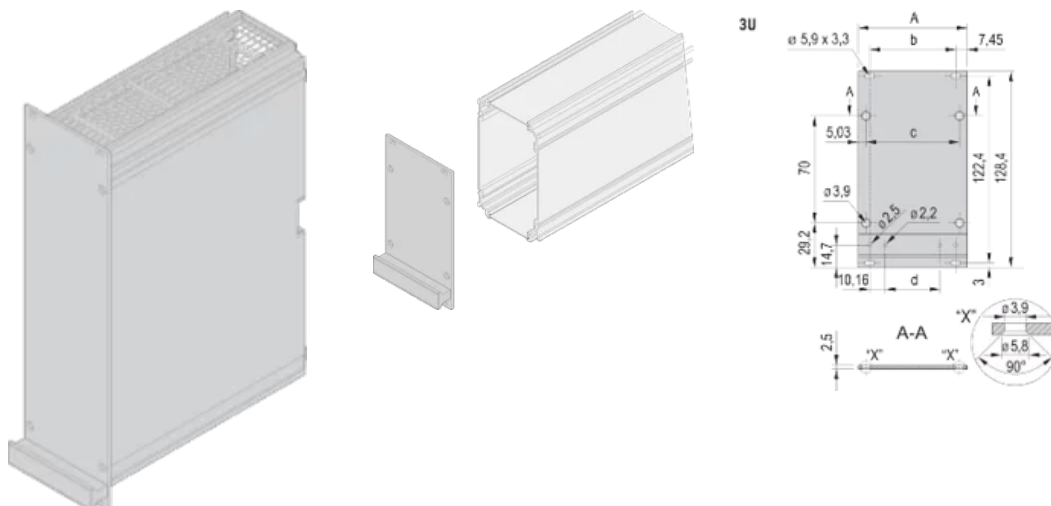

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE