


Telescopic Slide Slim Line, Length 559 mm

KATALOGOVÉ ČÍSLO

60110-440

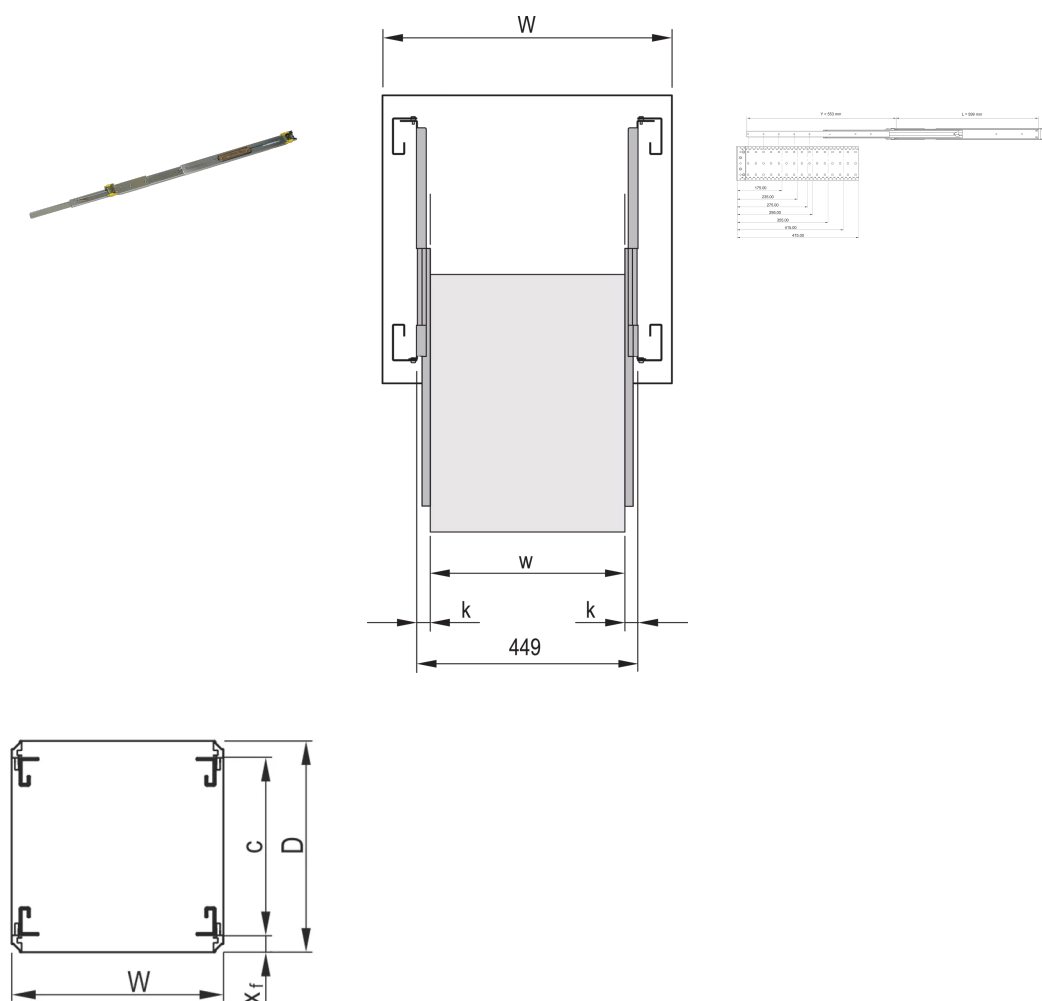

Narrow Telescopic Slide for Subracks with > 100 % extension.

CERTIFICATIONS



VLASTNOSTI

Suitable for 84 HP width subracks (type F, type H, type L)

Locks at full extension

Hinged

Extension length > 100 %

Rail width 7.5 mm

Maximum clear width of extension/drawer w = 84 HP (435 mm)

VLASTNOSTI PRODUKTU

Length: 559mm

Množství v balení: 2

Povrchová úprava: Pozinkovaná Ocel

Materiál: Ocel

Product Type: Telescopic Slide

Static Load: 15kg

Typ: Narrow

Net Weight: 2.123kg

DALŠÍ PODROBNOSTI O PRODUKTU

To mount on 19" plane please order assembly kit separately.

Telescopic slight can only be assembled to a subrack without an assembled rear angle or a modified rear angle (with special cutout).

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE