


Adjustable Monitor Arm

KATALOGOVÉ ČÍSLO

60118-562

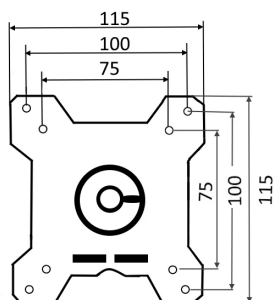

The collapsible articulate arm is ideal for a rack mounted stand workstation. It's an easy to install, rack-mountable appendage which allows for panoramic movement possibilities for a flat panel monitor in industrial environments

VLASTNOSTI

Support arm for mounting of flat panel monitor

Vesa Adapter 75x75 and 100x100 mm; Monitor size which can be mounted are of maximum "32

Fixing is to the side of the frame

Static load-carrying capacity (10 kg max.)

Support arm: Height-adjustable 300 mm; Angle of rotation on cabinet 180°; Monitor rotation angle 340° (fitted on cabinet 270°); Monitor tilt angle 60°; Integrated cable routing

Suitable for industrial and laboratory applications

VLASTNOSTI PRODUKTU

Product Type: Monitor Arm

Works With: Cabinet

Materiál: Ocel; Hliník; Plast

Net Weight: 2.85kg

Množství v balení: 1

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE