 



Connector Type H, EN 60603, DIN 41612, Female, 15 Contacts, FASTON 6.3 mm

KATALOGOVÉ ČÍSLO

69001-733

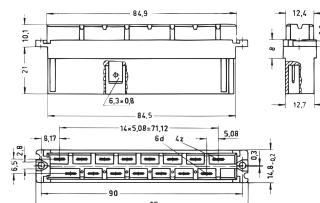

Male / Female DIN connector form H. Requirement class 2 as per EN 60603 (DIN 41642).

CERTIFICATIONS



VLASTNOSTI

Requirement class 2 as per EN 60603 (DIN 41642)

Separate Coding

Coding on the connector

VLASTNOSTI PRODUKTU

Typ: Female Connectors

Množství v balení: 1

Number of Contacts: 15

Contact Material: Silver Plated

Connector Pitch: 5.08mm

Min Creepage Distance, Contact-Contact: 8mm

Min Air Gap, Contact-Contact: 4.5mm

Max Current @ 20°C: 6A

Max Contact Resistance: 8mΩ

Max Insertion and Withdrawal Force: 90N

Test Voltage (Ueff), Contact-Contact: 1.55kV

Test Voltage (Ueff), Contact-Earth: 2.5kV

Row Assignment: Z; D

Povrchová úprava: Silver Plated

Product Type: Connector

Works With: Front Panels

Typ připojení: Faston, 6.3 mm

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE