 


EuropacPRO 19" Subrack Kit for Backplane, Shielded

EMC Shielded subrack for backplane mounting, rear side covered by a rear panel.



CERTIFICATIONS



VLASTNOSTI

Subrack with side panel type F ("flexible"), front 19" bracket included, depth-adjustable 19" bracket sold separately (not included in items delivered)

Supplied as space-saving flat-pack

Modifications such as cutouts, different finishes or dimensions available

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

IP 20, in accordance with IEC 60529

Aluminum construction

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Rear horizontal rail for backplane mounting with insulation strip

Horizontal rail type "light"

SPECIFIKACE

Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated

Product Type: Subrack/Chassis

EMC Shielding: Yes

Table 1/2

Katalogové číslo	Rack Height	Hloubka (D)	Množství v balení	For Mounting	Board Depth	Gasket Type
24563-142	3U	235mm	1	Backplane	160mm, 220mm	Textile EMC
24563-143	3U	295mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-144	3U	355mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-145	3U	415mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-146	3U	475mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-442	6U	235mm	1	Backplane	160mm, 220mm	Textile EMC
24563-443	6U	295mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-444	6U	355mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-445	6U	415mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-446	6U	475mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC

Table 2/2


Katalogové číslo	Rukojeť v ceně	Mounting	Complies With	Rack Width	Static Load	Rychlé odeslání
24563-142	No	Rack	IEC 60297-3-103	84HP	11kg	Ne
24563-143	No	Rack	IEC 60297-3-103	84HP	11kg	Ne
24563-144	No	Rack	IEC 60297-3-103	84HP	11kg	Ne

Katalogové číslo	Rukojeť v ceně	Mounting	Complies With	Rack Width	Static Load	Rychléodeslání
24563-145	No	Rack	IEC 60297-3-103	84HP	11kg	Ne
24563-146	No	Rack	IEC 60297-3-103	84HP	11kg	Ne
24563-442	No	Rack	IEC 60297-3-103	84HP	11kg	Ne
24563-443	No	Rack	IEC 60297-3-103	84HP	11kg	Ne
24563-444	No	Rack	IEC 60297-3-103	84HP	11kg	Ne
24563-445	No	Rack	IEC 60297-3-103	84HP	11kg	Ne
24563-446	No	Rack	IEC 60297-3-103	84HP	11kg	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

DIAGRAMS

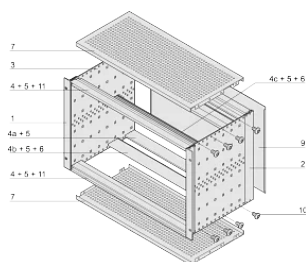

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE