


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, EN 50155

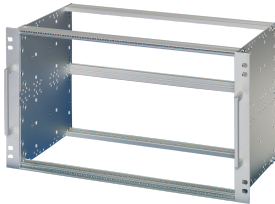

Subrack for Railway applications, conform to EN50155 standard, non-shielded.

CERTIFICATIONS



VLASTNOSTI

Shock and vibration tested to EN 50155, part 12.2.11

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Modifications such as cutouts, different finishes or dimensions available

IP 20, in accordance with IEC 60529

The double 19" screwing position adds to additionally safety (NFF standard)

Supplied as space-saving flat-pack

SPECIFIKACE

Static Load:	15kg
Materiál:	Hliník
EMC Shielding:	No
Product Type:	Subrack/Chassis

Table 1/3

Katalogové číslo	Rack Height	Hloubka	Množství v balení	For Mounting	Board Depth	EMC Gasket Type
21500-077	3U	235mm	1	Backplane	220mm	Textile
21500-078	6U	235mm	1	Backplane	220mm	Textile

Table 2/3

Katalogové číslo	Shock and Vibration Tolerance	Rukojeť v ceně	Mounting	Complies With	Povrchová úprava	Rack Width
21500-077	5g (force)	Yes	Rack	IEC 60297-3-103, EN 50155 part 12.2.11	Anodized, Passivated	84HP
21500-078	5g (force)	Yes	Rack	IEC 60297-3-103, EN 50155 part 12.2.11	Anodized, Passivated	84HP

Table 3/3

Katalogové číslo	Rychlé odeslání
21500-077	Ne
21500-078	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Test reports are available online.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE