


EuropacPRO 19" Subrack Kit for Railway, Shielded, SNCF

Subrack for Railway applications, conform to SNCF Standard.

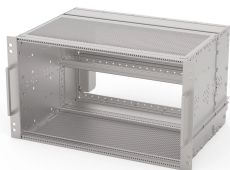

CERTIFICATIONS



VLASTNOSTI

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

Aluminum construction

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

SPECIFIKACE

Static Load:	15kg
Hloubka:	320mm

Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Complies With:	IEC 60297-3-103; SNCF NFF 61005; SNCF NFF 60002
Product Type:	Subrack/Chassis
EMC Shielding:	Yes

Table 1/2

Katalogové číslo	Rack Height	Rack Width	Množství v balení	For Mounting	Board Depth	Gasket Type
21500-028	6U	84HP	1	Backplane	220mm	Textile EMC
21500-071	6U	36HP	1	Backplane	220mm	Textile EMC
21500-068	3U	36HP	1	Backplane	220mm	Textile EMC
21500-030	3U	84HP	1	Backplane	220mm	Textile EMC

Table 2/2

Katalogové číslo	Shock and Vibration Tolerance	Rukojeť v ceně	Mounting	Certifications	Rychlé odeslání
21500-028	5g (force)	Yes	Rack	SNCF, RoHS	Ne
21500-071	5g (force)	Yes	Rack	RoHS	Ne
21500-068	5g (force)	Yes	Rack	RoHS	Ne
21500-030	5g (force)	Yes	Rack	SNCF, RoHS	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm.

Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná

instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE