


EuropacPRO Advanced EMC 45, 19" Subrack Kit for Backplane, Heavy, EMC Shielded, w/wo Front Handle

EMC Shielded subrack for backplane mounting, heavy version with tox welded side panels.

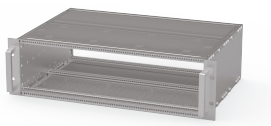

CERTIFICATIONS



VLASTNOSTI

Advanced EMC subrack with on average 45% improved RF shielding effectiveness compared to a standard EuropacPRO, tested according to EN 61000-5-7*Pending

Top and bottom covers with EMC and airflow optimized perforation, fulfills the requirements of the fire safety standard EN 62368-1

Additional side panel covers for increased lateral RF shielding

Horizontal rails and side panels of type H ("Heavy") for harsh environments

Rear horizontal rail for direct backplane mounting without insulation strip

Shock and vibration resistant up to 5 g, tested in accordance with EN 61373 class 1, category B

Installation load up to 15 kg

Compatible with textile and stainless-steel gaskets

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Versions with and without front handles

Supplied as space-saving flat-pack, modifications and assembly services on request

SPECIFIKACE

Static Load: 15kg
Product Type: Subrack/Chassis
EMC Shielding: Yes

Table 1/3

Katalogové číslo	Rack Height	Hloubka	Množství v balení	For Mounting	Board Depth	Gasket Type
24563-900	3U	235mm	1	Backplane	160mm	Textile EMC
24563-901	3U	295mm	1	Backplane	160mm	Textile EMC
24563-903	3U	355mm	1	Backplane	160mm	Textile EMC
24563-910	6U	235mm	1	Backplane	160mm	Textile EMC
24563-911	6U	295mm	1	Backplane	160mm	Textile EMC
24563-913	6U	355mm	1	Backplane	160mm	Textile EMC
24563-950	3U	235mm	1	Backplane	160mm	Textile EMC
24563-951	3U	295mm	1	Backplane	160mm	Textile EMC
24563-953	3U	355mm	1	Backplane	160mm	Textile EMC
24563-960	6U	235mm	1	Backplane	160mm	Textile EMC
24563-961	6U	295mm	1	Backplane	160mm	Textile EMC
24563-963	6U	355mm	1	Backplane	160mm	Textile EMC

Table 2/3

Katalogové číslo	Shock and Vibration Tolerance	Rukojeť v ceně	Mounting	Complies With	Povrchová úprava	Materiál
24563-900	5g (force)	Yes	Rack	IEC 60297-3-103	Anodized, Passivated	Hliník

Katalogové číslo	Shock and Vibration Tolerance	Rukojeť v ceně	Mounting	Complies With	Povrchová úprava	Materiál
24563-901	5g (force)	Yes	Rack	IEC 60297-3-103	Anodized, Passivated	Hliník
24563-903	5g (force)	Yes	Rack	IEC 60297-3-103	Anodized, Passivated	Hliník
24563-910	5g (force)	Yes	Rack	IEC 60297-3-103	Anodized, Passivated	Hliník
24563-911	5g (force)	Yes	Rack	IEC 60297-3-103	Anodized, Passivated	Hliník
24563-913	5g (force)	Yes	Rack	IEC 60297-3-103	Anodized, Passivated	Hliník
24563-950	5g (force)	No	Rack	IEC 60297-3-103	Anodized, Passivated	Hliník
24563-951	5g (force)	No	Rack	IEC 60297-3-103	Anodized, Passivated	Hliník
24563-953	5g (force)	No	Rack	IEC 60297-3-103	Anodized, Passivated	Hliník
24563-960	5g (force)	No	Rack	IEC 60297-3-103	Anodized, Passivated	Hliník
24563-961	5g (force)	No	Rack	IEC 60297-3-103	Anodized, Passivated	Hliník
24563-963	5g (force)	No	Rack	IEC 60297-3-103	Anodized, Passivated	Hliník

Table 3/3

Katalogové číslo	Rack Width	Rychlé odeslání
24563-900	84HP	Ne
24563-901	84HP	Ne
24563-903	84HP	Ne
24563-910	84HP	Ne
24563-911	84HP	Ne

Katalogové číslo	Rack Width	Rychlé odeslání
24563-913	84HP	Ne
24563-950	84HP	Ne
24563-951	84HP	Ne
24563-953	84HP	Ne
24563-960	84HP	Ne
24563-961	84HP	Ne
24563-963	84HP	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE