


EuropacPRO Advanced EMC 45 Top and Bottom Covers, Screwed to Side Panel, Ø 2.3mm

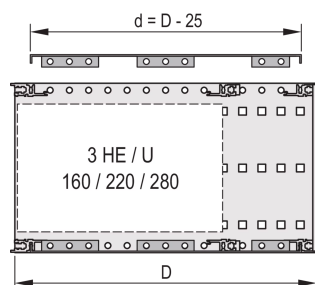

A cover plate is used for electromagnetic shielding or as mechanical protection. The cover can be screwed onto the side panel.

CERTIFICATIONS



VLASTNOSTI

Top and bottom covers with EMC and airflow optimized perforation, fulfills the requirements of the fire safety standard EN 62368-1, perforation diameter Ø 2.3mm, degree 50%

For variable positioning of horizontal rails e.g. for PCBs with standard formats

Cover plate for bolting to the side panel

Suitable for use with all horizontal rails, besides Rugged

SPECIFIKACE

Materiál:	Hliník
Product Type:	Cover Plate
Produktová řada:	EuropacPRO
Povrchová úprava:	Passivated
Typ:	Perforated
Works With:	Sub racks

Table 1/1

Katalogové číslo	Rack Width	Hloubka	Množství v balení	Balení	Rychlé odeslání
------------------	------------	---------	-------------------	--------	-----------------

24563-560	42HP	175mm	2	Pair	Ne
24563-556	36HP	235mm	2	Pair	Ne
24563-660	63HP	175mm	2	Pair	Ne
24563-760	84HP	175mm	2	Pair	Ne
24563-761	84HP	235mm	2	Pair	Ne
24563-762	84HP	275mm	2	Pair	Ne
24563-764	84HP	295mm	2	Pair	Ne
24563-766	84HP	415mm	2	Pair	Ne
24563-765	84HP	355mm	2	Pair	Ne
24563-555	36HP	175mm	2	Pair	Ne
24563-561	42HP	235mm	2	Pair	Ne
24563-562	42HP	275mm	2	Pair	Ne
24563-563	42HP	277.75mm	2	Pair	Ne
24563-564	42HP	295mm	2	Pair	Ne
24563-661	63HP	235mm	2	Pair	Ne
24563-662	63HP	275mm	2	Pair	Ne
24563-663	63HP	295mm	2	Pair	Ne
24563-763	84HP	277.75mm	2	Pair	Ne
24563-767	84HP	495mm	2	Pair	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE