


EuropacPRO Advanced EMC Plus, Dual Mesh Top and Bottom Covers, Screwed to Side Panel

NEW PRODUCT

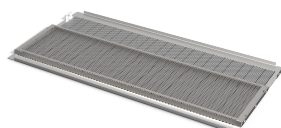

A cover plate is used for electromagnetic shielding and as mechanical protection. The cover can be screwed onto the side panel.

VLASTNOSTI

Dual mesh top and bottom covers with EMC and airflow optimized perforation, for highest RF-shielding requirements

Fulfills the requirements of the fire safety standard EN 62368-1

For PCBs with standard formats

Cover plate for bolting to the side panel

Suitable for use with all horizontal rails, besides Rugged

SPECIFIKACE

Materiál:	Hliník
Product Type:	Cover Plate
Produktová řada:	EuropacPRO
Povrchová úprava:	Passivated
Typ:	Perforated
Works With:	Sub racks

Table 1/1

Katalogové číslo	Hloubka	Množství v balení	Rack Width	Board Depth	Balení	Rychlé odeslání
24563-770	175mm	2	84HP	160mm	Pair	Ne
24563-771	235mm	2	84HP	160mm	Pair	Ne

Katalogové číslo	Hloubka	Množství v balení	Rack Width	Board Depth	Balení	Rychléodeslání
24563-772	275mm	2	84HP	160mm	Pair	Ne
24563-780	235mm	2	84HP	220mm	Pair	Ne
24563-774	295mm	2	84HP	160mm	Pair	Ne
24563-781	295mm	2	84HP	220mm	Pair	Ne
24563-773	277.75mm	2	84HP	160mm	Pair	Ne
24563-775	355mm	2	84HP	160mm	Pair	Ne
24563-776	415mm	2	84HP	160mm	Pair	Ne
24563-777	475mm	2	84HP	160mm	Pair	Ne
24563-782	355mm	2	84HP	220mm	Pair	Ne
24563-783	415mm	2	84HP	220mm	Pair	Ne
24563-784	475mm	2	84HP	220mm	Pair	Ne
24563-790	295mm	2	84HP	280mm	Pair	Ne
24563-791	355mm	2	84HP	280mm	Pair	Ne
24563-792	415mm	2	84HP	280mm	Pair	Ne
24563-793	475mm	2	84HP	280mm	Pair	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE