


Front Handle One-Piece, Width 12.2 mm

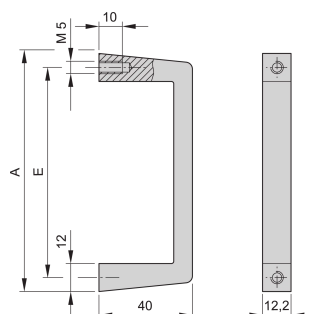

The handle can be assembled to a subrack or 19" front panel. Available with clear or black anodized surface. Handles will be bolted from the rear side.

CERTIFICATIONS



VLASTNOSTI

Static load-carrying capacity 30 kg/pair

Bolted from rear

SPECIFIKACE

Materiál:	Hliník
Produktová řada:	EuropacPRO
Product Type:	Handle
Works With:	Subracks

Table 1/2

Katalogové číslo	Rack Height	Povrchová úprava	Množství v balení	Typ rukojeti	Barva	Torque
10501-116	1U	Anodized	1	Straight	Silver	
10501-016	2U	Anodized	1	Straight	Silver	

Katalogové číslo	Rack Height	Povrchová úprava	Množství v balení	Typ rukojeti	Barva	Torque
10501-004	2U	Anodized	1	Straight	Silver	
10501-025	2U	Anodized	1	Straight	Black	
10501-005	3U	Anodized	1	Straight	Silver	2.4N·m
10501-020	3U	Anodized	1	Angled Handle	Silver	2.4N·m
10501-026	3U	Anodized	1	Straight	Black	2.4N·m
10501-006	4U	Anodized	1	Straight	Silver	
10501-018	4U	Anodized	1	Straight	Silver	2.4N·m
10501-021	4U	Anodized	1	Angled Handle	Silver	2.4N·m
10501-027	4U	Anodized	1	Straight	Black	
10501-007	5U	Anodized	1	Straight	Silver	
10501-028	5U	Anodized	1	Straight	Black	
10501-022	6U	Anodized	1	Angled Handle	Silver	2.4N·m
10501-008	6U	Anodized	1	Straight	Silver	2.4N·m
10501-029	6U	Anodized	1	Straight	Black	2.4N·m

Table 2/2

Katalogové číslo	Rychlé odeslání
10501-116	Ne
10501-016	Ne
10501-004	Ne

Katalogové číslo	Rychlé odeslání
10501-025	Ne
10501-005	Ne
10501-020	Ne
10501-026	Ne
10501-006	Ne
10501-018	Ne
10501-021	Ne
10501-027	Ne
10501-007	Ne
10501-028	Ne
10501-022	Ne
10501-008	Ne
10501-029	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Please order assembly part kit separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE