

Front Panel, Anodized, Unshielded, Screw Assembly

Anodized front panel, unshielded version, Al, 2.5 mm.



CERTIFICATIONS



VLASTNOSTI

Partial width front panel, Al, 2.5 mm

Al, anodized

SPECIFIKACE

Hloubka (D):	2.5mm
Materiál:	Hliník
Povrchová úprava:	Anodized
Accessory Type:	Front panel
Product Type:	Front Panel
Typ:	Front Panel without Handle

Table 1/3

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Mounting	Front Finish	Rear Finish
30807-508	3U	3HP	1	Screw-on Front	Anodized	Anodized

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Mounting	Front Finish	Rear Finish
30807-481	3U	4HP	1	Screw-on Front	Anodized	Anodized
30818-741	6U	2HP	1	Screw-on Front	Anodized	Anodized
30807-510	3U	5HP	1	Screw-on Front	Anodized	Anodized
30807-482	3U	6HP	1	Screw-on Front	Anodized	Anodized
30807-509	3U	7HP	1	Screw-on Front	Anodized	Anodized
30807-484	3U	8HP	1	Screw-on Front	Anodized	Anodized
30807-483	3U	10HP	1	Screw-on Front	Anodized	Anodized
30807-777	6U	5HP	1	Screw-on Front	Anodized	Anodized
30807-485	3U	12HP	1	Screw-on Front	Anodized	Anodized
30807-752	6U	6HP	1	Screw-on Front	Anodized	Anodized
30807-501	3U	14HP	1	Screw-on Front	Anodized	Anodized
30807-833	6U	7HP	1	Screw-on Front	Anodized	Anodized
30807-779	6U	8HP	1	Screw-on Front	Anodized	Anodized
30807-487	3U	21HP	1	Screw-on Front	Anodized	Anodized
30807-753	6U	10HP	1	Screw-on Front	Anodized	Anodized
30807-755	6U	12HP	1	Screw-on Front	Anodized	Anodized
30807-496	3U	28HP	1	Screw-on Front	Anodized	Anodized
30807-758	6U	14HP	1	Screw-on Front	Anodized	Anodized

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Mounting	Front Finish	Rear Finish
30807-780	6U	16HP	1	Screw-on Front	Anodized	Anodized
30807-494	3U	42HP	1	Screw-on Front	Anodized	Anodized
30807-757	6U	21HP	1	Screw-on Front	Anodized	Anodized
30807-416	2U	84HP	1	Screw-on Front	Anodized	Anodized
30807-766	6U	28HP	1	Screw-on Front	Anodized	Anodized
30808-067	3U	63HP	1	Screw-on Front	Anodized	Anodized
30807-506	3U	84HP	1	Screw-on Front	Anodized	Anodized
30807-764	6U	42HP	1	Screw-on Front	Anodized	Anodized
30807-596	4U	84HP	1	Screw-on Front	Anodized	Anodized
30807-771	6U	63HP	1	Screw-on Front	Anodized	Anodized
30807-776	6U	84HP	1	Screw-on Front	Anodized	Anodized
30807-778	6U	4HP	1	Screw-on Front	Anodized	Anodized
30810-432	3U	2HP	1	Screw-on Front	Anodized	Anodized

Table 2/3

Katalogové číslo	Treated Edges	Complies With	EMC Shielding	Výška (H)	Šířka (W)	Certifications
30807-508	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	14.9mm	RoHS
30807-481	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	20mm	RoHS
30818-741	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	9.8mm	RoHS

Katalogové číslo	Treated Edges	Complies With	EMC Shielding	Výška (H)	Šířka (W)	Certifications
30807-510	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	25mm	RoHS
30807-482	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	30.1mm	RoHS
30807-509	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	35.2mm	RoHS
30807-484	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	40.3mm	RoHS
30807-483	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	50.5mm	RoHS
30807-777	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	25mm	RoHS
30807-485	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	60.6mm	RoHS
30807-752	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	30.1mm	RoHS
30807-501	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	70.8mm	RoHS
30807-833	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	35.2mm	RoHS
30807-779	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	40.3mm	RoHS
30807-487	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	106.3mm	RoHS
30807-753	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	50.5mm	RoHS
30807-755	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	60.6mm	RoHS

Katalogové číslo	Treated Edges	Complies With	EMC Shielding	Výška (H)	Šířka (W)	Certifications
30807-496	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	141.9mm	RoHS
30807-758	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	70.8mm	RoHS
30807-780	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	80.9mm	RoHS
30807-494	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	213mm	RoHS
30807-757	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	106.3mm	RoHS
30807-416	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	84mm	426.4mm	RoHS
30807-766	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	141.9mm	RoHS
30808-067	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	319.7mm	RoHS
30807-506	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	426.4mm	RoHS
30807-764	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	213mm	RoHS
30807-596	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	172.9mm	426.4mm	
30807-771	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	319.7mm	RoHS
30807-776	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	426.4mm	RoHS
30807-778	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	20mm	RoHS

Katalogové číslo	Treated Edges	Complies With	EMC Shielding	Výška (H)	Šířka (W)	Certifications
30810-432	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	9.8mm	RoHS

Table 3/3


Katalogové číslo	Rychlé odeslání
30807-508	Ne
30807-481	Ne
30818-741	Ne
30807-510	Ne
30807-482	Ne
30807-509	Ne
30807-484	Ne
30807-483	Ne
30807-777	Ne
30807-485	Ne
30807-752	Ne
30807-501	Ne
30807-833	Ne
30807-779	Ne
30807-487	Ne

Katalogové číslo	Rychlé odeslání
30807-753	Ne
30807-755	Ne
30807-496	Ne
30807-758	Ne
30807-780	Ne
30807-494	Ne
30807-757	Ne
30807-416	Ne
30807-766	Ne
30808-067	Ne
30807-506	Ne
30807-764	Ne
30807-596	Ne
30807-771	Ne
30807-776	Ne
30807-778	Ne
30810-432	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Please order fixing material (sleeves, collar screws) separately.

DIAGRAMS

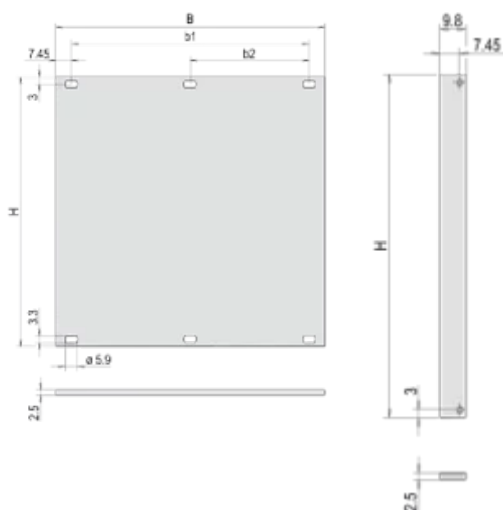

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE