


Front Panel EMC Textile Shielding Kit, -40 up to +70°C

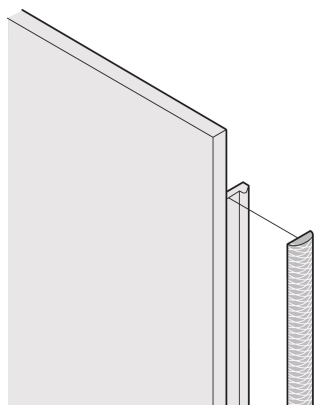

The textile EMC gaskets are inserted into a slot on the right hand side of the U-shaped front panels. The gaskets are glued to the front panel.

CERTIFICATIONS



VLASTNOSTI

Textile EMC gasket is affixed laterally on the front panel or in the groove of the right-hand profile as appropriate.

Profile seal is bonded onto the contact surface of the 19" bracket or of the rear angle and sets up the conductive connection to the U-shaped front panels

Temperature range -40 °C ... +70 °C

SPECIFIKACE

Works With:	Subracks; Cases; Front Panels
Produktová řada:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; Frame Type Plug-In Unit
Product Type:	Shielding Kit
Materiál:	Termoplastický Elastomer

Table 1/2

Katalogové číslo	Rack Height	Množství v balení	Hloubka (D)	Výška (H)	Šířka (W)	Flammability Rating
------------------	-------------	-------------------	-------------	-----------	-----------	---------------------

21101-978	5U	10				
21101-857	2U	10	1.62mm	52mm	3.8mm	UL® 94V-0
21101-853	3U	10	1.62mm	97mm	3.8mm	UL® 94V-0
21101-858	4U	10				
21101-854	3U	100	1.62mm	97mm	3.8mm	UL® 94V-0
21101-855	6U	10	1.62mm	232mm	3.8mm	UL® 94V-0
21101-856	6U	100	1.62mm	232mm	3.8mm	UL® 94V-0
21101-904	9U	100				
21101-859	9U	10	1.62mm	365.5mm	3.8mm	UL® 94V-0


Table 2/2

Katalogové číslo	Rychlé odeslání
21101-978	Ne
21101-857	Ne
21101-853	Ne
21101-858	Ne
21101-854	Ne
21101-855	Ne
21101-856	Ne
21101-904	Ne
21101-859	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

EMC gaskets (textile) are required for shielding the front panels.

DIAGRAMS

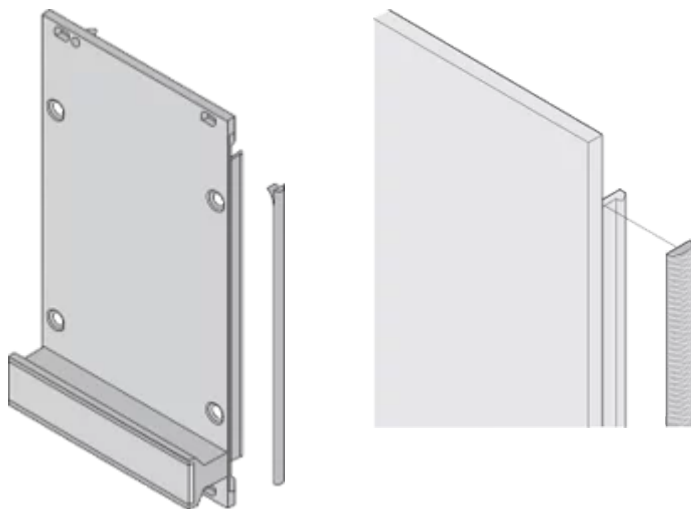

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE