


Front Panel, Flat, Refrofit Shielding, D-Sub Cutouts

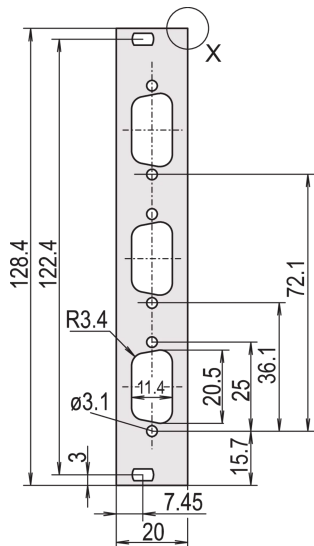

Flat front panel with cutout for D-Sub connectors.
Shieldable for stainless steel EMC gasket.

CERTIFICATIONS



VLASTNOSTI

For stainless steel EMC gasket

Al, 2.5 mm, front anodized, conductive

SPECIFIKACE

Rack Height:	3U
Rack Width:	4HP
Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel

Typ: Front Panel without Handle

EMC Shielding: No (Retrofittable)

Table 1/2

Katalogové číslo	Množství v balení	Mounting	Gasket Type	Front Finish	Rear Finish	Number of Pins
30118-353	1	Screw-on Front	Stainless Steel EMC	Anodized	Conductive	(2) 25
30118-352	1	Screw-on Front	Stainless Steel EMC	Anodized	Conductive	(2) 15
30118-351	1	Screw-on Front	Stainless Steel EMC	Anodized	Conductive	(2) 9
30118-354	1	Screw-on Front	Stainless Steel EMC	Anodized	Conductive	(3) 9
30118-350	1	Screw-on Front	Stainless Steel EMC	Anodized	Conductive	(1) 25
30118-348	1	Screw-on Front	Stainless Steel EMC	Anodized	Conductive	(1) 9
30118-349	1	Screw-on Front	Stainless Steel EMC	Anodized	Conductive	(1) 15

Table 2/2

Katalogové číslo	Treated Edges	Complies With	Hloubka (D)	Výška (H)	Šířka (W)	Rychlé odeslání
30118-353	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Ne
30118-352	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Ne
30118-351	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Ne
30118-354	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Ne
30118-350	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Ne
30118-348	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Ne

Katalogové číslo	Treated Edges	Complies With	Hloubka (D)	Výška (H)	Šířka (W)	Rychléodeslání
30118-349	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Ne

DALŠÍ PODROBNOSTI O PRODUKTU


Please order fixing material (sleeves, collar screws) separately.


Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

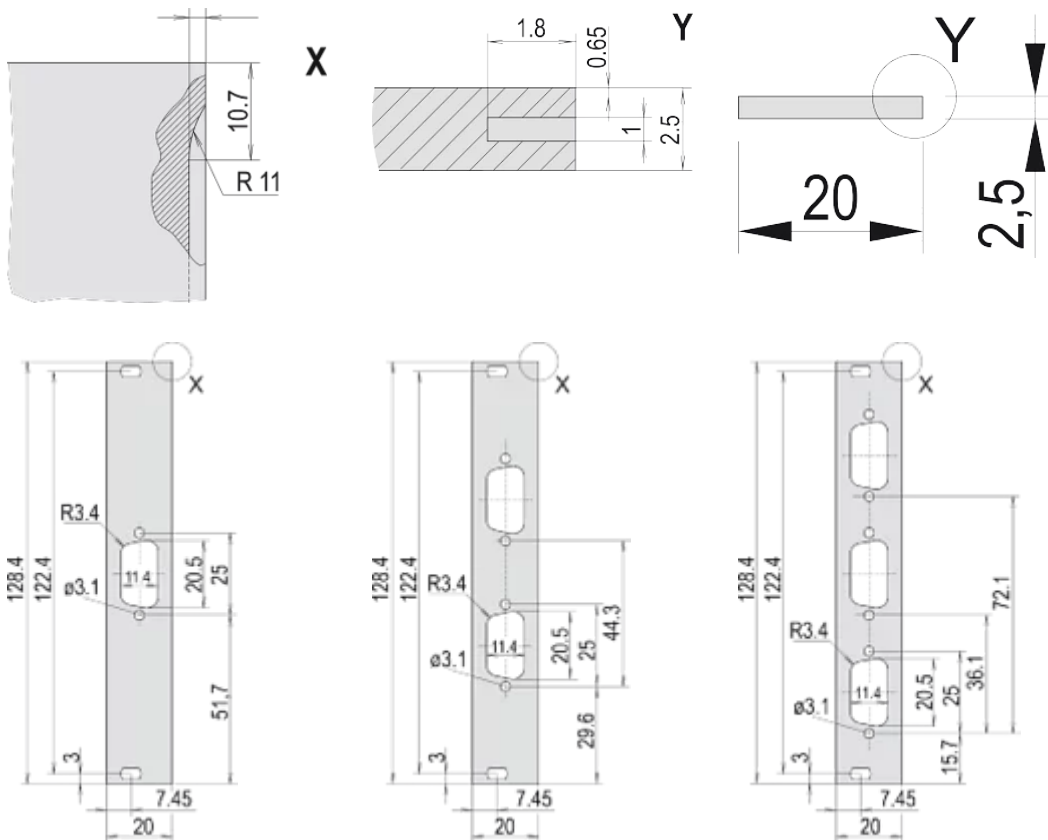

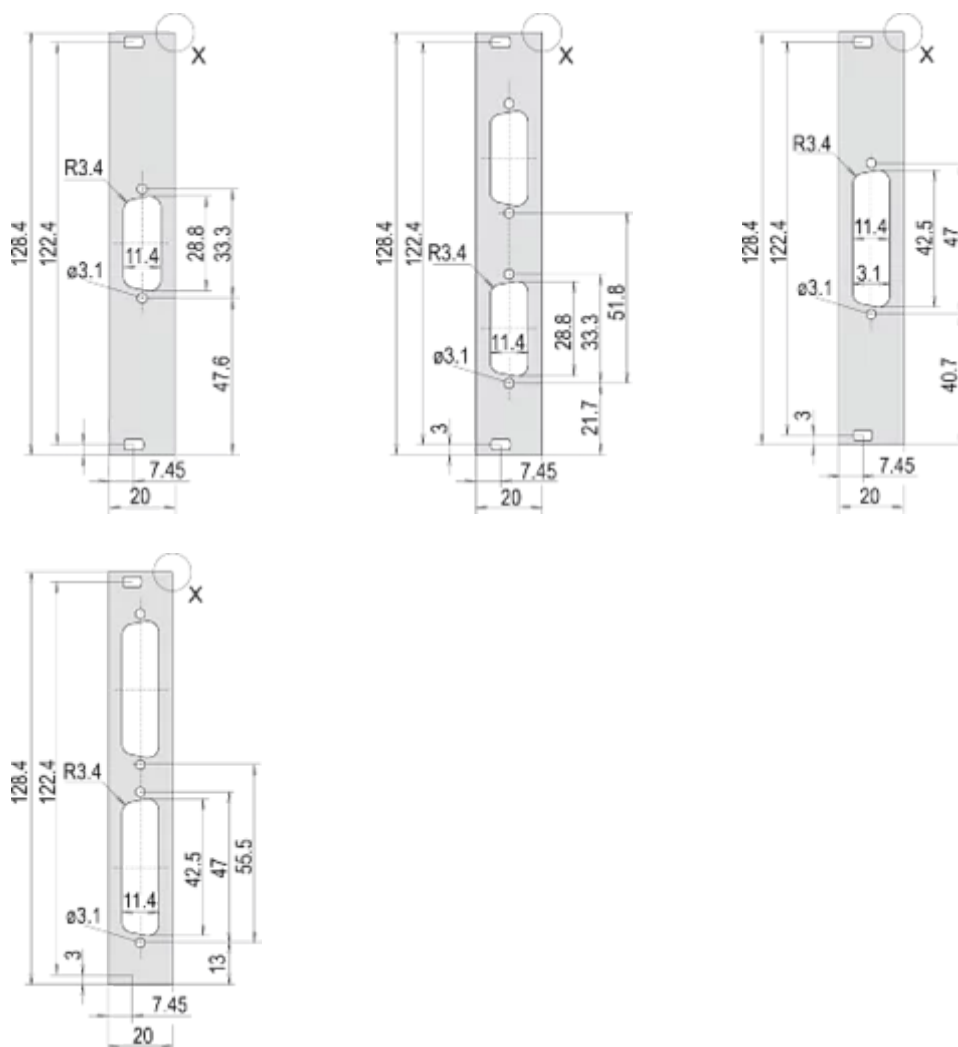

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE