


Front Panel, Flat, Unshielded, D-Sub Cutouts

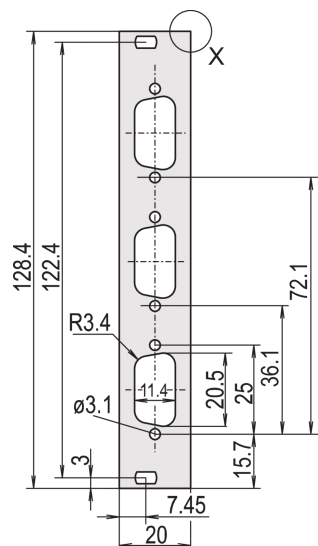

Flat front panel with cutout for D-Sub connectors.
Unshielded version.

CERTIFICATIONS



VLASTNOSTI

Non-shielded version

Al, 2.5 mm, front anodized, rear conductive

SPECIFIKACE

Rack Height:	3U
Rack Width:	4HP
Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Typ:	Front Panel without Handle

Table 1/2

Katalogové číslo	Množství v balení	Mounting	Front Finish	Rear Finish	Number of Pins	Treated Edges
30118-346	1	Screw-on Front	Anodized	Conductive	(2) 25	No
30118-347	1	Screw-on Front	Anodized	Conductive	(3) 9	No
30118-344	1	Screw-on Front	Anodized	Conductive	(2) 9	No
30118-345	1	Screw-on Front	Anodized	Conductive	(2) 15	No
30118-343	1	Screw-on Front	Anodized	Conductive	(1) 25	No
30118-342	1	Screw-on Front	Anodized	Conductive	(1) 15	No
30118-341	1	Screw-on Front	Anodized	Conductive	(3) 9	No

Table 2/2

Katalogové číslo	Complies With	Hloubka (D)	EMC Shielding	Výška (H)	Šířka (W)	Rychlé odeslání
30118-346	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm	Ne
30118-347	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm	Ne
30118-344	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm	Ne
30118-345	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm	Ne
30118-343	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm	Ne
30118-342	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm	Ne
30118-341	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm	Ne


DALŠÍ PODROBNOSTI O PRODUKTU


Delivery is in standard pack multiples. Pricing is per individual item.

Please order fixing material (sleeves, collar screws) separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

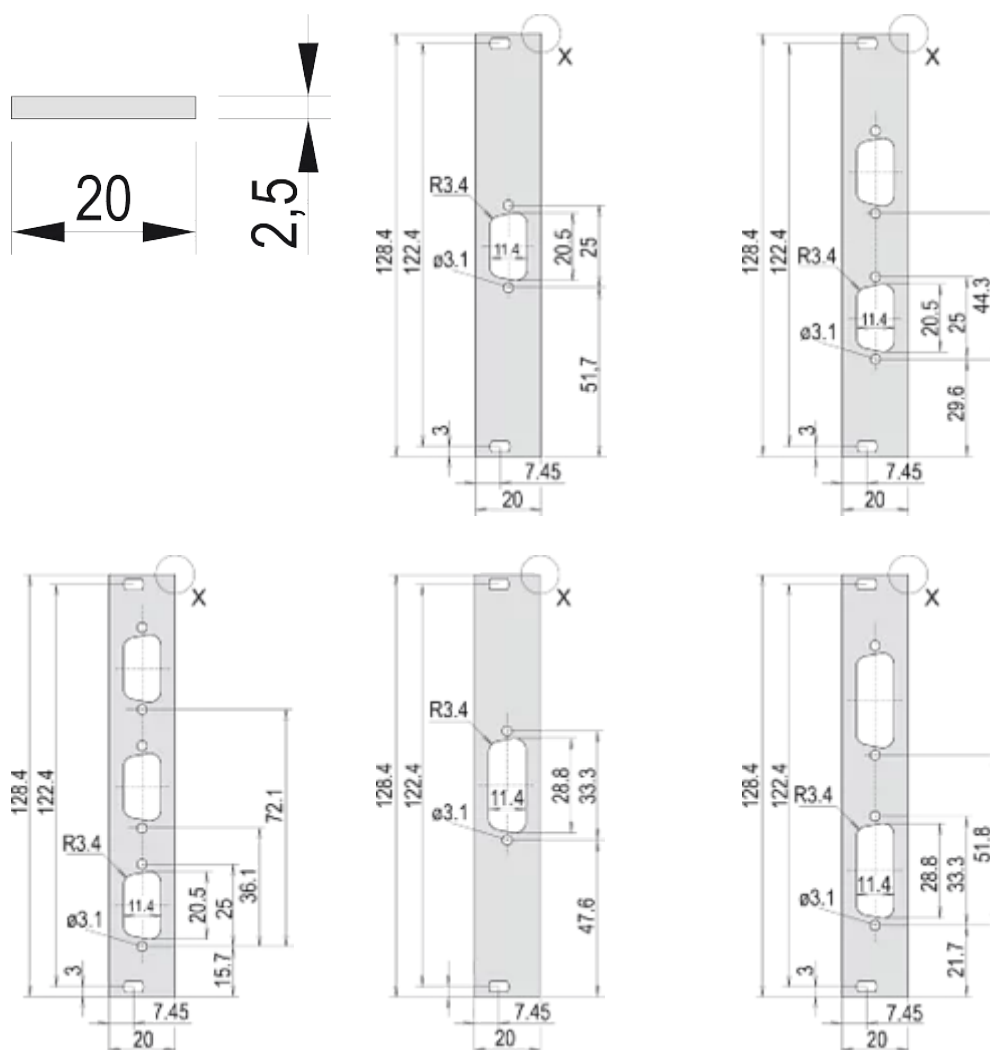

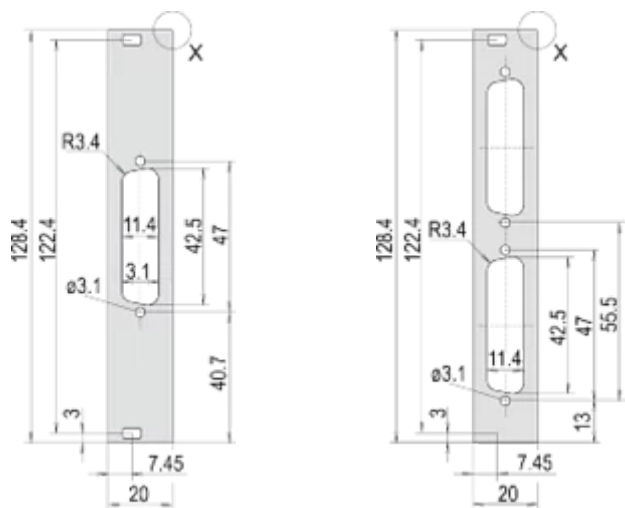

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE