


Front Panel, Full Width, Slotted, Unshielded, for RatiopacPRO

Full-width front panel, slotted, unshielded.

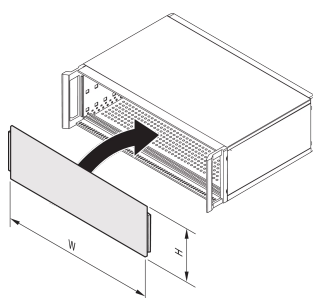

CERTIFICATIONS



VLASTNOSTI

Inserted between side panel and molded parts such as trim, 19" mounting bracket or handle

Front panels can also be used as rear panels

Fixes without screws (special horizontal rails cover the edges of the front panel and hold them in place)

Shielded (rear conductive); for a conductive connection with the case please order EMC sealing (stainless steel) separately

SPECIFIKACE

Hloubka (D):	2.5mm
Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Front Finish	Rear Finish	Treated Edges
------------------	-------------	------------	-------------------	--------------	-------------	---------------

34571-617	2U	28HP	1	Anodized	Conductive	No
34571-618	2U	42HP	1	Anodized	Conductive	No
34571-605	3U	28HP	1	Anodized	Conductive	No
34571-609	4U	28HP	1	Anodized	Conductive	No
34571-606	3U	42HP	1	Anodized	Conductive	No
34571-619	2U	63HP	1	Anodized	Conductive	No
34571-621	5U	28HP	1	Anodized	Conductive	No
34571-620	2U	84HP	1	Anodized	Conductive	No
34571-610	4U	42HP	1	Anodized	Conductive	No
34571-613	6U	28HP	1	Anodized	Conductive	No
34571-607	3U	63HP	1	Anodized	Conductive	No
34571-622	5U	42HP	1	Anodized	Conductive	No
34571-608	3U	84HP	1	Anodized	Conductive	No
34571-611	4U	63HP	1	Anodized	Conductive	No
34571-614	6U	42HP	1	Anodized	Conductive	No
34571-623	5U	63HP	1	Anodized	Conductive	No
34571-612	4U	84HP	1	Anodized	Conductive	No
34571-615	6U	63HP	1	Anodized	Conductive	No
34571-624	5U	84HP	1	Anodized	Conductive	No


34571-616	6U	84HP	1	Anodized	Conductive	No
-----------	----	------	---	----------	------------	----

Table 2/2

Katalogové číslo	Výška (H)	Šířka (W)	Rychlé odeslání
34571-617	84mm	141.9mm	Ne
34571-618	84mm	213.2mm	Ne
34571-605	128.4mm	141.9mm	Ne
34571-609	172.9mm	141.9mm	Ne
34571-606	128.4mm	213.2mm	Ne
34571-619	84mm	319.7mm	Ne
34571-621	217.3mm	141.9mm	Ne
34571-620	84mm	426.4mm	Ne
34571-610	172.9mm	213.2mm	Ne
34571-613	261.8mm	141.9mm	Ne
34571-607	128.4mm	319.7mm	Ne
34571-622	217.3mm	213.2mm	Ne
34571-608	128.4mm	426.4mm	Ne
34571-611	172.9mm	319.7mm	Ne
34571-614	261.8mm	213.2mm	Ne
34571-623	217.3mm	319.7mm	Ne
34571-612	172.9mm	426.4mm	Ne

Katalogové číslo	Výška (H)	Šířka (W)	Rychlé odeslání
34571-615	261.8mm	319.7mm	Ne
34571-624	217.3mm	426.4mm	Ne
34571-616	261.8mm	426.4mm	Ne

DIAGRAMS

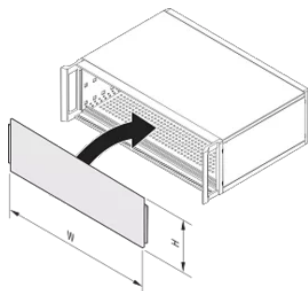

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE