

# Front Panel, Retrofit Shielding



Flat front panel. Shieldable with stainless steel EMC gasket.

## CERTIFICATIONS



## VLASTNOSTI

For stainless steel EMC gasket

Al, 2.5 mm, front anodized, conductive

## SPECIFIKACE

|                        |                            |
|------------------------|----------------------------|
| <b>Hloubka (D):</b>    | 2.5mm                      |
| <b>Materiál:</b>       | Hliník                     |
| <b>Accessory Type:</b> | Front panel                |
| <b>Product Type:</b>   | Front Panel                |
| <b>Typ:</b>            | Front Panel without Handle |
| <b>EMC Shielding:</b>  | No (Retrofittable)         |

Table 1/3

| Katalogové číslo | Rack Height | Rack Width | Množství v balení | Mounting       | Gasket Type         | Front Finish |
|------------------|-------------|------------|-------------------|----------------|---------------------|--------------|
| 20846-425        | 3U          | 3HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |

| Katalogové číslo | Rack Height | Rack Width | Množství v balení | Mounting       | Gasket Type         | Front Finish |
|------------------|-------------|------------|-------------------|----------------|---------------------|--------------|
| 30846-865        | 6U          | 2HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-426        | 3U          | 4HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-427        | 3U          | 5HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-428        | 3U          | 6HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-429        | 3U          | 7HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-443        | 6U          | 4HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-430        | 3U          | 8HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-442        | 6U          | 3HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-431        | 3U          | 10HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-444        | 6U          | 5HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-432        | 3U          | 12HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-445        | 6U          | 6HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-433        | 3U          | 14HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-446        | 6U          | 7HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-424        | 3U          | 16HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-447        | 6U          | 8HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-448        | 6U          | 10HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-434        | 3U          | 21HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |

| Katalogové číslo | Rack Height | Rack Width | Množství v balení | Mounting       | Gasket Type         | Front Finish |
|------------------|-------------|------------|-------------------|----------------|---------------------|--------------|
| 20846-449        | 6U          | 12HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-436        | 3U          | 28HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-450        | 6U          | 14HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-456        | 6U          | 16HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-451        | 6U          | 21HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-437        | 3U          | 42HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 30846-588        | 2U          | 84HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-452        | 6U          | 28HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-438        | 3U          | 63HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 30846-676        | 3U          | 84HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-453        | 6U          | 42HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 30846-683        | 4U          | 84HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 20846-454        | 6U          | 63HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 30846-771        | 6U          | 84HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 30846-859        | 9U          | 84HP       | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |
| 30846-864        | 3U          | 2HP        | 1                 | Screw-on Front | Stainless Steel EMC | Anodized     |

Table 2/3

| Katalogové číslo | Rear Finish | Treated Edges | Complies With | Povrchová úprava | Výška (H) | Šířka (W) |
|------------------|-------------|---------------|---------------|------------------|-----------|-----------|
|------------------|-------------|---------------|---------------|------------------|-----------|-----------|

|           |            |    |                                 |          |         |        |
|-----------|------------|----|---------------------------------|----------|---------|--------|
| 20846-425 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 128.4mm | 14.9mm |
| 30846-865 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 261.8mm | 9.8mm  |
| 20846-426 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 128.4mm | 20mm   |
| 20846-427 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 128.4mm | 25mm   |
| 20846-428 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 128.4mm | 30.1mm |
| 20846-429 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 128.4mm | 35.2mm |
| 20846-443 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 261.8mm | 20mm   |
| 20846-430 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 128.4mm | 40.3mm |
| 20846-442 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 261.8mm | 14.9mm |
| 20846-431 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 128.4mm | 50.5mm |
| 20846-444 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 261.8mm | 25mm   |
| 20846-432 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 128.4mm | 60.6mm |
| 20846-445 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 261.8mm | 30.1mm |
| 20846-433 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 128.4mm | 70.8mm |
| 20846-446 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 261.8mm | 35.2mm |

|           |            |    |                                 |                      |         |         |
|-----------|------------|----|---------------------------------|----------------------|---------|---------|
| 20846-424 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized             | 128.4mm | 80.9mm  |
| 20846-447 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized             | 261.8mm | 40.3mm  |
| 20846-448 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized             | 261.8mm | 50.5mm  |
| 20846-434 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized             | 128.4mm | 106.3mm |
| 20846-449 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized             | 261.8mm | 60.6mm  |
| 20846-436 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized             | 128.4mm | 141.9mm |
| 20846-450 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized             | 261.8mm | 70.8mm  |
| 20846-456 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized             | 261.8mm | 80.9mm  |
| 20846-451 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized             | 261.8mm | 106.3mm |
| 20846-437 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized             | 128.4mm | 213mm   |
| 30846-588 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized, Passivated | 84mm    | 426.4mm |
| 20846-452 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized             | 261.8mm | 141.9mm |
| 20846-438 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized             | 128.4mm | 319.7mm |
| 30846-676 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized, Passivated | 128.4mm | 426.4mm |
| 20846-453 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized             | 261.8mm | 213mm   |

|           |            |    |                                 |          |         |         |
|-----------|------------|----|---------------------------------|----------|---------|---------|
| 30846-683 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 172.9mm | 426.4mm |
| 20846-454 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 261.8mm | 319.7mm |
| 30846-771 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 261.8mm | 426.4mm |
| 30846-859 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 395.1mm | 426.4mm |
| 30846-864 | Conductive | No | IEC 60297-3-101, IEEE 1101.1/10 | Anodized | 128.4mm | 9.8mm   |

Table 3/3

| Katalogové číslo | Rychlé odeslání |
|------------------|-----------------|
| 20846-425        | Ne              |
| 30846-865        | Ne              |
| 20846-426        | Ne              |
| 20846-427        | Ne              |
| 20846-428        | Ne              |
| 20846-429        | Ne              |
| 20846-443        | Ne              |
| 20846-430        | Ne              |
| 20846-442        | Ne              |
| 20846-431        | Ne              |
| 20846-444        | Ne              |


| Katalogové číslo | Rychlé odeslání |
|------------------|-----------------|
| 20846-432        | Ne              |
| 20846-445        | Ne              |
| 20846-433        | Ne              |
| 20846-446        | Ne              |
| 20846-424        | Ne              |
| 20846-447        | Ne              |
| 20846-448        | Ne              |
| 20846-434        | Ne              |
| 20846-449        | Ne              |
| 20846-436        | Ne              |
| 20846-450        | Ne              |
| 20846-456        | Ne              |
| 20846-451        | Ne              |
| 20846-437        | Ne              |
| 30846-588        | Ne              |
| 20846-452        | Ne              |
| 20846-438        | Ne              |
| 30846-676        | Ne              |

| Katalogové číslo | Rychlé odeslání |
|------------------|-----------------|
| 20846-453        | Ne              |
| 30846-683        | Ne              |
| 20846-454        | Ne              |
| 30846-771        | Ne              |
| 30846-859        | Ne              |
| 30846-864        | Ne              |

## DALŠÍ PODROBNOSTI O PRODUKTU

Please order fixing material (sleeves, collar screws) separately.

## DIAGRAMS

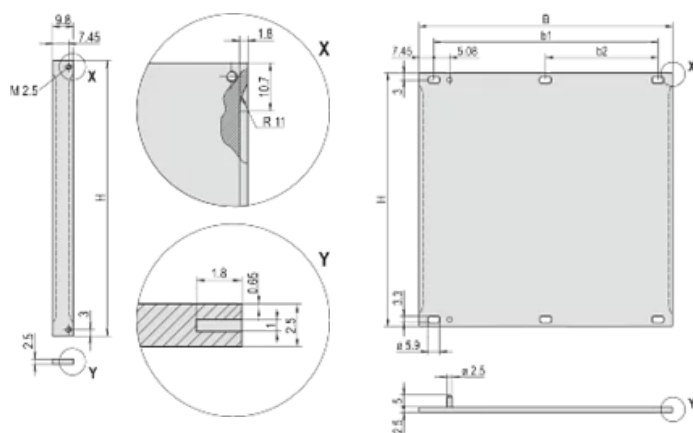

## UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na [www.nvent.com](http://www.nvent.com) a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Naše portfolio silných značek:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**