


Front Panel, U-shaped, Screwless Mounting for RatiopacPRO Style, Retrofit Shielding

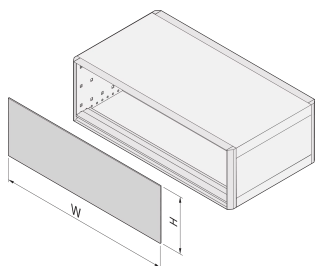

Front panel screwless, front side: anodized, rear side: conductive; unshielded

CERTIFICATIONS



VLASTNOSTI

Front panel, Al, 2.5 mm, front: anodized, rear: conductive; unshielded

Enables screwless mounting on horizontal rails

SPECIFIKACE

Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Works With:	Cases
Product Type:	Front Panel
Typ:	Front Panel
Produktová řada:	RatiopacPRO Style; RatiopacPRO

Table 1/1

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Výška	Šířka	Rychlé odeslání
34572-199	2U	28HP	1	84mm	141.9mm	Ne

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Výška	Šířka	Rychléodeslání
34572-203	3U	28HP	1	128.4mm	141.9mm	Ne
34572-200	2U	42HP	1	84mm	213.2mm	Ne
34572-207	4U	28HP	1	172.9mm	141.9mm	Ne
34572-201	2U	63HP	1	84mm	319.7mm	Ne
34572-204	3U	42HP	1	128.4mm	213.2mm	Ne
34572-202	2U	84HP	1	84mm	426.4mm	Ne
34572-208	4U	42HP	1	172.9mm	213.2mm	Ne
34572-205	3U	63HP	1	128.4mm	319.7mm	Ne
34572-206	3U	84HP	1	128.4mm	426.4mm	Ne
34572-209	4U	63HP	1	172.9mm	319.7mm	Ne
34572-210	4U	84HP	1	172.9mm	426.4mm	Ne
34572-225	6U	63HP	1	261.8mm	319.7mm	Ne
34572-226	6U	84HP	1	261.8mm	426.4mm	Ne
34572-223	6U	28HP	1	261.8mm	141.9mm	Ne
34572-224	6U	42HP	1	261.8mm	213.2mm	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE