


Interscale Fan Holder With Fans

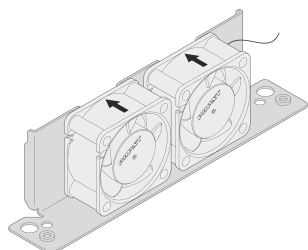

Interscale Fan Holder With Fans, for desktop cases and 19" chassis. Available in different sizes and with three fan versions, with a air flow volume from 10 to 170 m³/h.

VLASTNOSTI

Fan holder for mounting on bottom of case

Fans are simple to fit to the fan holder using vibration-damping fixing material

Fan holders fix into desktop case with 2 plastic feet or into 19" case with 2 screws

Fan holder cannot be used in conjunction with the mounting plate (instead use mounting plate with integrated fan holder)

For technical data of fans, please see delivery includes

SPECIFIKACE

Povrchová úprava: Aluminum-Zinc Plated

Typ: Fan Tray

Product Type: Fan Unit

Vstupní napětí DC: 12V min

Table 1/2

Katalogové číslo	Šířka	Hloubka	Množství v balení	Max Static Pressure	Max Ambient Temperature	Průtok vzduchu
24830-101	80mm	25mm	1	95.41Pa	70°C	109m³/h
24828-104	40mm	20mm	1		70°C	10m³/h
24830-102	80mm	25mm	1			

Katalogové číslo	Šířka	Hloubka	Množství v balení	Max Static Pressure	Max Ambient Temperature	Průtok vzduchu
24828-105	40mm	20mm	1		70°C	10m³/h
24828-204	80mm	25mm	1		70°C	19m³/h
24828-205	80mm	25mm	1		70°C	19m³/h
24828-107	40mm	20mm	1		70°C	10m³/h
24828-305	119mm	25mm	1		70°C	170m³/h
24828-207	80mm	25mm	1		70°C	19m³/h
24828-307	119mm	25mm	1		70°C	170m³/h

Table 2/2

Katalogové číslo	Noise Level	Výška	Materiál	Power	Produktová řada	Rychlé odeslání
24830-101	44.62dB(A)	80mm	Ocel			Ne
24828-104	18dB(A)	40mm	Ocel	0.9W	Interscale	Ne
24830-102		80mm	Ocel			Ne
24828-105	18dB(A)	40mm	Ocel	0.9W	Interscale	Ne
24828-204	32dB(A)	80mm	Ocel	2W	Interscale	Ne
24828-205	32dB(A)	80mm	Ocel	2W	Interscale	Ne
24828-107	18dB(A)	40mm	Ocel	0.9W	Interscale	Ne
24828-305	43dB(A)	119mm	Ocel	5.3W	Interscale	Ne
24828-207	32dB(A)	80mm	Ocel	2W	Interscale	Ne

Katalogové číslo	Noise Level	Výška	Materiál	Power	Produktová řada	Rychléodeslání
24828-307	43dB(A)	119mm	Ocel	5.3W	Interscale	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE