


Outdoor Unibody VENT Cabinet

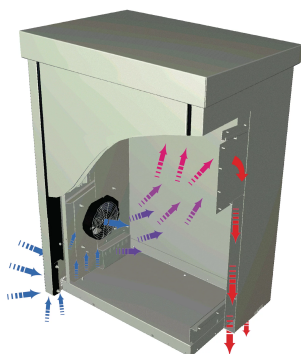

Telecom and Railway applications require sophisticated electronics in outdoor setups. nVent SCHROFF Outdoor cabinets shield such electronic components from extreme weather and vandalism, ensuring operational continuity.

CERTIFICATIONS



VLASTNOSTI

Double-walled, Al

Forced heat dissipation via fan assembled in side panel, max. 35 W/K

IP 55

One-piece inner case with removable outer cladding

SPECIFIKACE

Materiál: Hliník

Table 1/3

Katalogové číslo	Product Type	Produktová řada	Rack Height	Výška	Šířka	Hloubka
11249-007	Outdoor Cabinet	Unibody	16U	930mm	700mm	500mm
11249-012	Outdoor Cabinet	Unibody	25U	1330mm	700mm	500mm

Katalogové číslo	Product Type	Produktová řada	Rack Height	Výška	Šířka	Hloubka
11249-009	Outdoor Cabinet	Unibody	20U	1100mm	700mm	500mm

Table 2/3

Katalogové číslo	Wall Type	Door Type	Access	Cooling	EMC Shielding	Complies With
11249-007	Double Walled	Single Door	Front	Fan Ventilation	No	IEC 61969-1, IEC 61969-2, IEC 60917-1, IEC 60917-2, ETS 300119, IEC 60529, DIN EN 50178, VDE 0160
11249-012	Double Walled	Single Door	Front	Fan Ventilation	No	IEC 61969-1, IEC 61969-2, IEC 60917-1, IEC 60917-2, ETS 300119, IEC 60529, DIN EN 50178, VDE 0160
11249-009	Double Walled	Single Door	Front	Fan Ventilation	No	IEC 61969-1, IEC 61969-2, IEC 60917-1, IEC 60917-2, ETS 300119, IEC 60529, DIN EN 50178, VDE 0160

Table 3/3

Katalogové číslo	Množství v balení	Povrchová úprava	Rychlé odeslání
11249-007	1	Strukturovaný Práškový	Ano
11249-012	1	Strukturovaný Práškový	Ano
11249-009	1	Strukturovaný Práškový	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Please order wall-mounting assembly kit separately.

Further base/plinth heights on request.

Please order panel/slide mounts separately.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE