

Plug-In Unit Front Panel for Static Trapezoid Handle



The front panel enables the assembly of a plastic or Alu-profile static trapezoid handle. The front panel cannot be shielded with a textile gasket.

CERTIFICATIONS



VLASTNOSTI

Front panel, unshielded

Front panel, Al, 2.5 mm, front anodized, conductive

SPECIFIKACE

Hloubka (D):	2.5mm
Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Typ:	Front Panel for Handle (PIU)

Table 1/3

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Typ rukojeti	Mounting	Front Finish
------------------	-------------	------------	-------------------	--------------	----------	--------------

30847-602	3U	3HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-603	3U	4HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-604	3U	5HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-605	3U	6HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-625	6U	3HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-606	3U	7HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-607	3U	8HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-626	6U	4HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-608	3U	10HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-627	6U	5HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-629	6U	7HP	1	Trapezoid, Static	Screw-on Front	Anodized
30847-609	3U	12HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized

30847-628	6U	6HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-630	6U	8HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-631	6U	10HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-632	6U	12HP	1	Trapezoid, Static	Screw-on Front	Anodized

Table 2/3

Katalogové číslo	Rear Finish	Treated Edges	Complies With	EMC Shielding	Výška (H)	Šířka (W)
30847-602	Conductive	No	IEC 60297-3-101	No	128.4mm	14.9mm
30847-603	Conductive	No	IEC 60297-3-101	No	128.4mm	20mm
30847-604	Conductive	No	IEC 60297-3-101	No	128.4mm	25mm
30847-605	Conductive	No	IEC 60297-3-101	No	128.4mm	30.1mm
30847-625	Conductive	No	IEC 60297-3-101	No	261.8mm	14.9mm
30847-606	Conductive	No	IEC 60297-3-101	No	128.4mm	35.2mm
30847-607	Conductive	No	IEC 60297-3-101	No	128.4mm	40.3mm
30847-626	Conductive	No	IEC 60297-3-101	No	261.8mm	20mm
30847-608	Conductive	No	IEC 60297-3-101	No	128.4mm	50.5mm
30847-627	Conductive	No	IEC 60297-3-101	No	261.8mm	25mm
30847-629	Conductive	No	IEC 60297-3-101	No	261.8mm	35.2mm


Katalogové číslo	Rear Finish	Treated Edges	Complies With	EMC Shielding	Výška (H)	Šířka (W)
30847-609	Conductive	No	IEC 60297-3-101	No	128.4mm	60.6mm
30847-628	Conductive	No	IEC 60297-3-101	No	261.8mm	30.1mm
30847-630	Conductive	No	IEC 60297-3-101	No	261.8mm	40.3mm
30847-631	Conductive	No	IEC 60297-3-101	No	261.8mm	50.5mm
30847-632	Conductive	No	IEC 60297-3-101	No	261.8mm	60.6mm

Table 3/3

Katalogové číslo	Rychlé odeslání
30847-602	Ne
30847-603	Ne
30847-604	Ne
30847-605	Ne
30847-625	Ne
30847-606	Ne
30847-607	Ne
30847-626	Ne
30847-608	Ne
30847-627	Ne
30847-629	Ne
30847-609	Ne

Katalogové číslo	Rychlé odeslání
30847-628	Ne
30847-630	Ne
30847-631	Ne
30847-632	Ne

DIAGRAMS

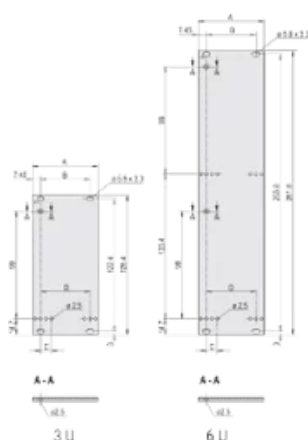

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE