

Plug-In Unit Kit With IEL Handle, Shielded, Black, 3 U



Plug-in unit, with IEL inserter/extractor black handle, 3 U, front assembly. The U-shaped front panel enable shielding with a textile gasket.

CERTIFICATIONS



VLASTNOSTI

U-shaped front panel for textile gasket

Suitable for insertion and extraction forces up to 700 N (per pair)

Enable the installation of a microswitch

Enable the installation of coding pegs in accordance with IEC 60297-3-103/ IEEE 1101.10

SPECIFIKACE

Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Product Type:	Front Panel
Typ:	Front Panel with Handle (PIU)

Table 1/3

Katalogové číslo	Rack Width	Množství v balení	Typ rukojeti	Mounting	Gasket Type	Front Finish
------------------	------------	-------------------	--------------	----------	-------------	--------------


20848-585	4HP	1	IEL	Screw-on Front	Textile EMC	Anodized
20848-589	8HP	1	IEL	Screw-on Front	Textile EMC	Anodized
20848-591	12HP	1	IEL	Screw-on Front	Textile EMC	Anodized
20848-587	6HP	1	IEL	Screw-on Front	Textile EMC	Anodized
20848-590	10HP	1	IEL	Screw-on Front	Textile EMC	Anodized

Table 2/3						
Katalogové číslo	Rear Finish	Treated Edges	Complies With	EMC Shielding	Výška (H)	Rack Height
20848-585	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4mm	3U
20848-589	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4mm	3U
20848-591	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4mm	3U
20848-587	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4mm	3U
20848-590	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4mm	3U

Table 3/3		
Katalogové číslo	Šířka (W)	Rychlé odeslání
20848-585	20mm	Ne

Katalogové číslo	Šířka (W)	Rychlé odeslání
20848-589	40.3mm	Ne
20848-591	60.6mm	Ne
20848-587	30.1mm	Ne
20848-590	50.5mm	Ne

DIAGRAMS

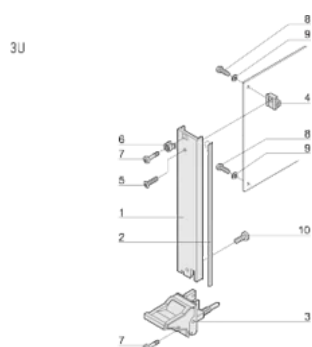

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE