


Plug-In Unit Kit With IEL Handle, Shielded, Black, 6 U

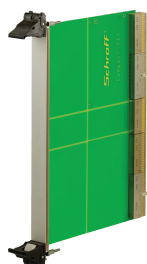

Plug-in unit, with IEL inserter/extractor black handle, 6 U, front assembly. The U-shaped front panel enable shielding with a textile gasket.

CERTIFICATIONS



VLASTNOSTI

U-shaped front panel for textile gasket

Suitable for insertion and extraction forces up to 700 N (per pair)

Enable the installation of a microswitch

Enable the installation of coding pegs in accordance with IEC 60297-3-103/ IEEE 1101.10

SPECIFIKACE

Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Product Type:	Front Panel
Typ:	Front Panel with Handle (PIU)

Table 1/3

Katalogové číslo	Rack Width	Množství v balení	Typ rukojeti	Mounting	Front Finish	Rear Finish
------------------	------------	-------------------	--------------	----------	--------------	-------------

20848-592	4HP	1	IEL	Screw-on Front, Screw-on Rear IO	Anodized	Etched
20848-594	6HP	1	IEL	Screw-on Front, Screw-on Rear IO	Anodized	Etched
20848-596	8HP	1	IEL	Screw-on Front, Screw-on Rear IO	Anodized	Etched
20848-597	10HP	1	IEL	Screw-on Front, Screw-on Rear IO	Anodized	Etched
20848-598	12HP	1	IEL	Screw-on Front, Screw-on Rear IO	Anodized	Etched

Table 2/3


Katalogové číslo	Treated Edges	Complies With	EMC Shielding	Výška (H)	Rack Height	Šířka (W)
20848-592	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U	20mm
20848-594	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U	30.1mm
20848-596	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U	40.3mm
20848-597	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U	50.5mm
20848-598	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U	60.6mm

Table 3/3

Katalogové číslo	Rychlé odeslání
------------------	-----------------

20848-592	Ne
20848-594	Ne
20848-596	Ne
20848-597	Ne
20848-598	Ne

DIAGRAMS

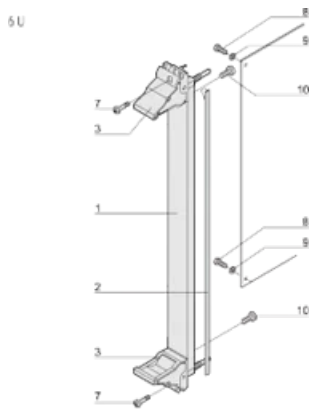

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE