

Plug-In Unit Kit With XL Handle, Shielded, Black, 6 U



The XL handle is used for applications which requires high insertion / extraction forces such as VPX or VXS standards. Suitable for insertion and extractions forces up to 1500N (per pair).

CERTIFICATIONS



VLASTNOSTI

For applications which requires high insertion / extraction forces such as VPX or VXS standards

Additional board fixing options available

Handle requires additional die cast fixing block (combination with horizontal rail short / long lip)

U-shaped front panel for textile gasket

Suitable for insertion/extraction forces up to 1500 N (per pair)

IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10

SPECIFIKACE

Rack Height:	6U
Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Product Type:	Front Panel
Typ:	Front Panel with Handle (PIU)
EMC Shielding:	Yes

Table 1/2

Katalogové číslo	Rack Width	Množství v balení	Typ rukojeti	Mounting	Gasket Type	Front Finish
20848-770	8HP	1	XL	Screw-on Front	Textile EMC	Anodized
20848-771	12HP	1	XL	Screw-on Front	Textile EMC	Anodized
20848-769	4HP	1	XL	Screw-on Front	Textile EMC	Anodized


Table 2/2

Katalogové číslo	Rear Finish	Treated Edges	Complies With	Výška (H)	Šířka (W)	Rychlé odeslání
20848-770	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEEE 1101.1	261.8mm	40.3mm	Ne
20848-771	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEEE 1101.1	261.8mm	60.6mm	Ne
20848-769	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEEE 1101.1	261.8mm	20mm	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Kit with front panel for micro switch on request.

DIAGRAMS

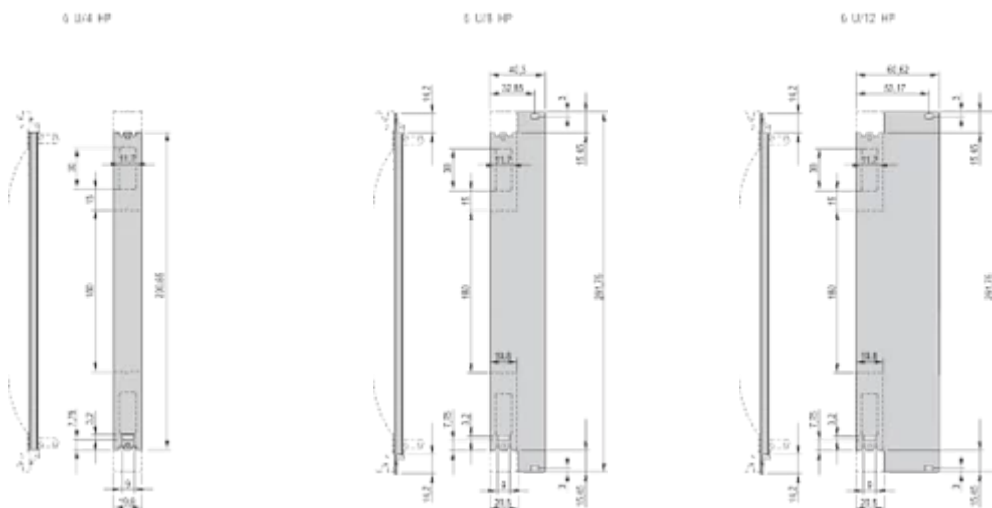

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE