


Plug-In Unit U-Profile Front Panel for Handle Form 1

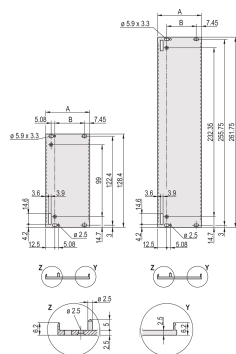

U-profile front panel. Enables the assembly of form 1 trapezoid form extraction handle. The front panel can be shielded with a textile gasket.

CERTIFICATIONS



VLASTNOSTI

Al profile, front anodized, rear conductive

Front panel, U-profile, shieldable

Alignment pin pressed-in, stainless steel

SPECIFIKACE

Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Typ:	Front Panel with Handle (PIU)
EMC Shielding:	No (Retrofittable)

Table 1/3

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Typ rukojeti	Mounting	Gasket Type
------------------	-------------	------------	-------------------	--------------	----------	-------------

30848-461	3U	4HP	1	Trapezoid, Type 1	Screw-on Front	Textile EMC
30848-463	3U	6HP	1	Trapezoid, Type 1	Screw-on Front	Textile EMC
30848-465	3U	8HP	1	Trapezoid, Type 1	Screw-on Front	Textile EMC
30848-468	6U	4HP	1	Trapezoid, Type 1	Screw-on Front	Textile EMC
30848-466	3U	10HP	1	Trapezoid, Type 1	Screw-on Front	Textile EMC
30848-467	3U	12HP	1	Trapezoid, Type 1	Screw-on Front	Textile EMC
30848-470	6U	6HP	1	Trapezoid, Type 1	Screw-on Front	Textile EMC
30848-472	6U	8HP	1	Trapezoid, Type 1	Screw-on Front	Textile EMC
30848-473	6U	10HP	1	Trapezoid, Type 1	Screw-on Front	Textile EMC
30848-474	6U	12HP	1	Trapezoid, Type 1	Screw-on Front	Textile EMC

Table 2/3

Katalogové číslo	Front Finish	Rear Finish	Treated Edges	Complies With	Hloubka (D)	Výška (H)
30848-461	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm
30848-463	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm
30848-465	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm
30848-468	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm
30848-466	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm
30848-467	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm

Katalogové číslo	Front Finish	Rear Finish	Treated Edges	Complies With	Hloubka (D)	Výška (H)
30848-470	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm
30848-472	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm
30848-473	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm
30848-474	Anodized	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm

Table 3/3


Katalogové číslo	Šířka (W)	Rychlé odeslání
30848-461	20mm	Ne
30848-463	30.1mm	Ne
30848-465	40.3mm	Ne
30848-468	20mm	Ne
30848-466	50.5mm	Ne
30848-467	60.6mm	Ne
30848-470	30.1mm	Ne
30848-472	40.3mm	Ne
30848-473	50.5mm	Ne
30848-474	60.6mm	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Please order EMC profile seal separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

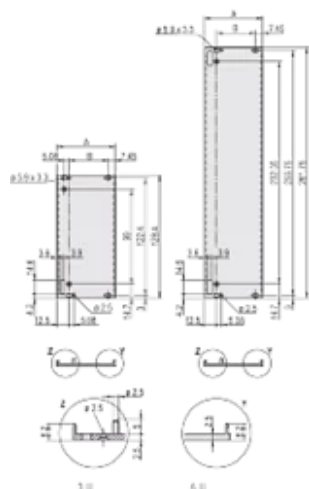

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE