

Plug-In Unit U-Profile Front Panel for IEL, IET, Handle, 3 U



U-Profile front panel can be shielded with a textile gasket. It can be combined with the IEL and IET or the type 2 handle in trapezoid form.

CERTIFICATIONS



VLASTNOSTI

For IEL/IET/Trapeziform Type 2 handle

Al extrusion, 2.5 mm, front anodized, rear conductive

U profile, shieldable with textile EMC gasket

Front panel, 3 U, for front mounting

Manufacturing process causes various surface structures to appear between 4 to 12 HP and 14 to 16 HP

Stainless steel alignment pin pressed-in

SPECIFIKACE

Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Typ:	Front Panel for Handle (PIU)

Table 1/3

Katalogové číslo	Rack Width	Množství v balení	Typ rukojeti	Mounting	EMC Gasket Type	Front Finish
30848-299	9HP	1	IEL, IET, Trapezoid, Type 2	Screw-on Front	Textile	Anodized
20848-228	11HP	1	IEL, IET, Trapezoid, Type 2	Screw-on Front	Textile	Anodized
20848-230	14HP	1	IEL, IET, Trapezoid, Type 2	Screw-on Front	Textile	Anodized
20848-232	16HP	1	IEL, IET, Trapezoid, Type 2	Screw-on Front	Textile	Anodized

Table 2/3

Katalogové číslo	Rear Finish	Treated Edges	Complies With	Hloubka (D)	EMC Shielding	Výška (H)
30848-299	Conductive	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	2.5mm	No (Retrofittable)	128.4mm
20848-228	Conductive	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	2.5mm	No (Retrofittable)	128.4mm
20848-230	Conductive	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	2.5mm	No (Retrofittable)	128.4mm
20848-232	Conductive	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	2.5mm	No (Retrofittable)	128.4mm

Table 3/3

Katalogové číslo	Rack Height	Šířka (W)	Certifications	Rychlé odeslání
30848-299	3U	45.38mm		Ne
20848-228	3U	55.54mm	RoHS	Ne


Katalogové číslo	Rack Height	Šířka (W)	Certifications	Rychlé odeslání
20848-230	3U	70.8mm	RoHS	Ne
20848-232	3U	80.9mm	RoHS	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Please order EMC profile seal separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

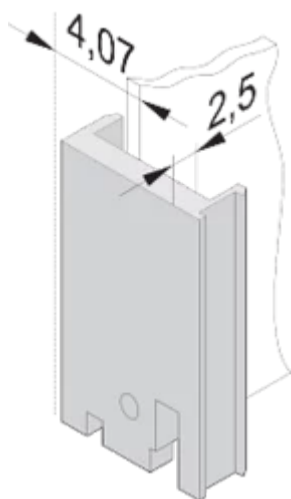

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE