


Plug-In Unit U-Profile Front Panel for XL Handle

Front panel for XL handle. Shieldable with textile gasket. with or without cutout for a microswitch.

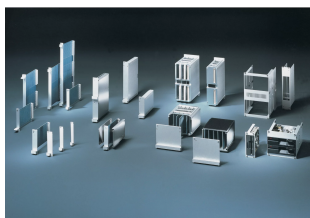

CERTIFICATIONS



VLASTNOSTI

Al, front anodized, sides and rear conductive

Suitable for sleeve and collar screw

U-front profile, shieldable, for inserter/extractor handle, type XL

SPECIFIKACE

Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Typ:	Front Panel for Handle (PIU)
EMC Shielding:	No (Retrofittable)

Table 1/3

Katalogové číslo	Rack Width	Množství v balení	Typ rukojeti	Mounting	EMC Gasket Type	Front Finish
30849-153	4HP	1	XL	Screw-on Front	Textile	Anodized

Katalogové číslo	Rack Width	Množství v balení	Typ rukojeti	Mounting	EMC Gasket Type	Front Finish
30849-154	4HP	1	XL	Screw-on Front	Textile	Anodized
30849-156	8HP	1	XL	Screw-on Front	Textile	Anodized
30849-155	8HP	1	XL	Screw-on Front	Textile	Anodized
30849-158	12HP	1	XL	Screw-on Front	Textile	Anodized
30849-157	12HP	1	XL	Screw-on Front	Textile	Anodized

Table 2/3

Katalogové číslo	Rear Finish	Treated Edges	Complies With	Hloubka (D)	Výška (H)	Rack Height
30849-153	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-154	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-156	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-155	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-158	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-157	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U

Table 3/3

Katalogové číslo	Šířka (W)	Rychlé odeslání
30849-153	20mm	Ne
30849-154	20mm	Ne
30849-156	40.3mm	Ne


Katalogové číslo	Šířka (W)	Rychlé odeslání
30849-155	40.3mm	Ne
30849-158	60.6mm	Ne
30849-157	60.6mm	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Delivery is exclusively in standard pack quantity, Please order EMC textile gasket and microswitch separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

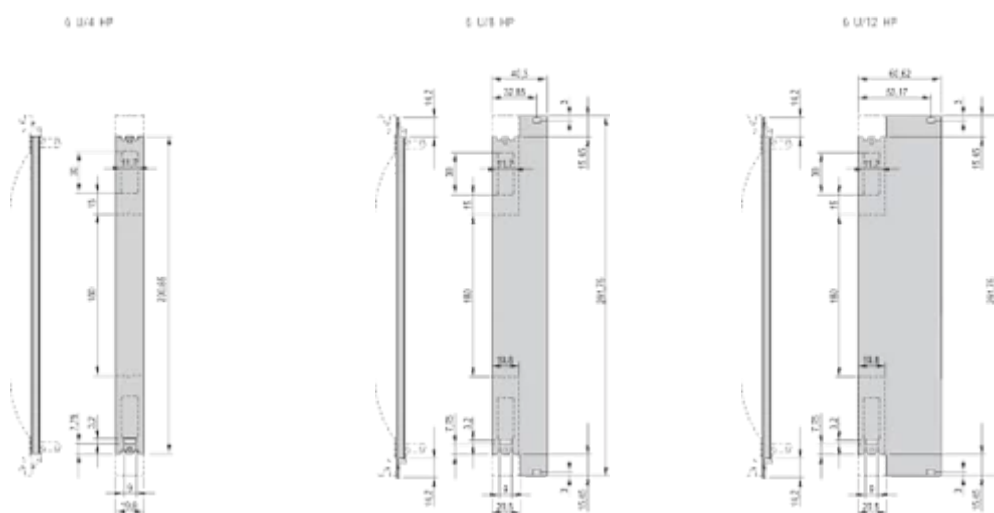

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE