


PropacPRO EMC Rear Panel, Full Width

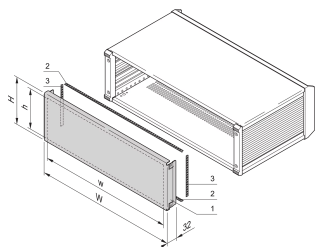

The EMC rear panel, full width for PropacPRO Case mounts to the frame of the case. It has no perforation. The shielding is done with textile EMC gaskets.

CERTIFICATIONS



VLASTNOSTI

Alu panel, 1.5 mm, with fastener for Earthing / GND

Mounts on case (left, right)

Without perforation

SPECIFIKACE

Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Works With:	Cases
Produktová řada:	PropacPRO
Typ:	Rear Panel
Product Type:	Side Panel

Table 1/1

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Rychlé odeslání
24576-244	2U	42HP	1	Ne
24576-247	3U	28HP	1	Ne

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Rychlé odeslání
24576-248	3U	42HP	1	Ne
24576-245	2U	63HP	1	Ne
24576-252	4U	42HP	1	Ne
24576-249	3U	63HP	1	Ne
24576-250	3U	84HP	1	Ne
24576-253	4U	63HP	1	Ne
24576-254	4U	84HP	1	Ne
24576-258	6U	84HP	1	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE