


PropacPRO Front Panel, Full Width, Unshielded

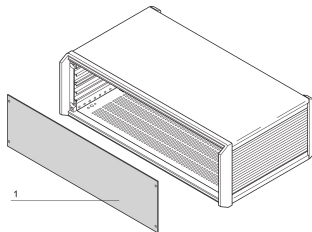

The front panel, full width for PropacPRO Case mounts to the frame of the case.

CERTIFICATIONS



VLASTNOSTI

Al panel, 2.0 mm (84 HP 2.5 mm)

SPECIFIKACE

Materiál:	Hliník
Povrchová úprava:	Anodized
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Front Finish	Rear Finish	Treated Edges
20850-128	2U	42HP	1	Anodized	Anodized	No
20850-134	3U	28HP	1	Anodized	Anodized	No
20850-129	2U	63HP	1	Anodized	Anodized	No

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Front Finish	Rear Finish	Treated Edges
20850-135	3U	42HP	1	Anodized	Anodized	No
20850-142	4U	42HP	1	Anodized	Anodized	No
20850-136	3U	63HP	1	Anodized	Anodized	No
20850-130	2U	84HP	1	Anodized	Anodized	No
20850-143	4U	63HP	1	Anodized	Anodized	No
20850-137	3U	84HP	1	Anodized	Anodized	No
20850-144	4U	84HP	1	Anodized	Anodized	No
20850-158	6U	84HP	1	Anodized	Conductive	No

Table 2/2				
Katalogové číslo	Hloubka	Výška	Šířka	Rychlé odeslání
20850-128	2mm	84mm	238.7mm	Ne
20850-134	2mm	128.5mm	167.6mm	Ne
20850-129	2mm	84mm	345.4mm	Ne
20850-135	2mm	128.5mm	238.7mm	Ne
20850-142	2mm	172.9mm	238.7mm	Ne
20850-136	2mm	128.5mm	345.4mm	Ne
20850-130	2.5mm	84mm	452mm	Ne
20850-143	2mm	172.9mm	345.4mm	Ne
20850-137	2.5mm	128.5mm	452mm	Ne

Katalogové číslo	Hloubka	Výška	Šířka	Rychlé odeslání
20850-144	2.5mm	172.9mm	452mm	Ne
20850-158	2.5mm	261.8mm	452mm	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE