


PropacPRO Rear Hood

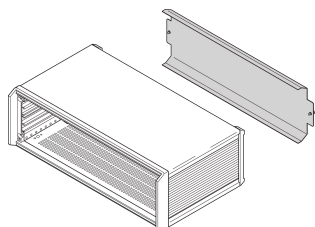

The rear hood can be assembled onto a rear panel of a PropacPRO case. The rear hood enables an additional space between the rear panel and the hood to provide space to store a cable. Can be unscrewed from the rear side.

CERTIFICATIONS



VLASTNOSTI

Al material 1.0 mm, RAL 9006

The fixing is done with two knurled screws

SPECIFIKACE

Materiál:	Hliník
Works With:	Cases
Product Type:	Cover
Povrchová úprava:	Strukturovaný Práškový
Produktová řada:	PropacPRO
Typ:	Rear Hood

Table 1/1

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Rychlé odeslání
24576-086	3U	42HP	1	Ne
24576-087	3U	63HP	1	Ne
24576-091	4U	63HP	1	Ne

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Rychlé odeslání
24576-088	3U	84HP	1	Ne
24576-092	4U	84HP	1	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

To install the rear hood, feet must be fitted to the rear panel; please order separately.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE