


PropacPRO Rear Panel, Full Width, Unshielded

The rear panel, full width for PropacPRO Case mounts to the frame of the case. With or without vented slots.

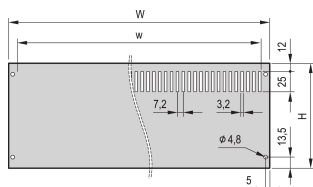

CERTIFICATIONS



VLASTNOSTI

Alu panel, 2.0 mm (84 HP 2.5 mm)

Mounting with support bracket on case (right and left)

SPECIFIKACE

Materiál:	Hliník
Povrchová úprava:	Anodized
Works With:	Cases
Produktová řada:	PropacPRO
Typ:	Rear Panel
Product Type:	Side Panel

Table 1/1

Katalogové číslo	Rack Height	Rack Width	Design Feature	Množství v balení	Rychlé odeslání
24576-144	2U	42HP	Perforated	1	Ne
24576-044	2U	42HP	Non-Perforated	1	Ne
24576-047	3U	28HP	Non-Perforated	1	Ne

Katalogové číslo	Rack Height	Rack Width	Design Feature	Množství v balení	Rychlé odeslání
24576-147	3U	28HP	Perforated	1	Ne
24576-145	2U	63HP	Perforated	1	Ne
24576-048	3U	42HP	Non-Perforated	1	Ne
24576-148	3U	42HP	Perforated	1	Ne
24576-045	2U	63HP	Non-Perforated	1	Ne
24576-149	3U	63HP	Perforated	1	Ne
24576-052	4U	42HP	Non-Perforated	1	Ne
24576-146	2U	84HP	Perforated	1	Ne
24576-152	4U	42HP	Perforated	1	Ne
24576-049	3U	63HP	Non-Perforated	1	Ne
24576-046	2U	84HP	Non-Perforated	1	Ne
24576-153	4U	63HP	Perforated	1	Ne
24576-053	4U	63HP	Non-Perforated	1	Ne
24576-150	3U	84HP	Perforated	1	Ne
24576-050	3U	84HP	Non-Perforated	1	Ne
24576-154	4U	84HP	Perforated	1	Ne
24576-054	4U	84HP	Non-Perforated	1	Ne
24576-158	6U	84HP	Perforated	1	Ne

Katalogové číslo	Rack Height	Rack Width	Design Feature	Množství v balení	Rychlé odeslání
24576-058	6U	84HP	Non-Perforated	1	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE