


PropacPRO Tip-Up Handle

Tip-up carrying handle.

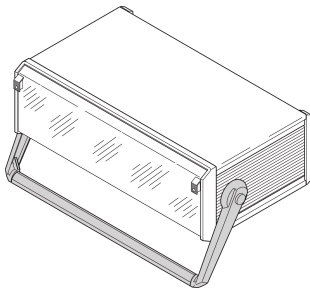

CERTIFICATIONS



VLASTNOSTI

Load-carrying capacity 20 kg

Can be locked in 30° increments

With powder-coated carrying bar

The handle enable a user to have a better view to the front side of the case in case of desktop usage

SPECIFIKACE

Materiál:	Hliník; Zinc Alloy
Works With:	Cases
Product Type:	Handle
Produktová řada:	PropacPRO

Table 1/1

Katalogové číslo	Rack Width	Množství v balení	Typ rukojeti	Rychlé odeslání
24576-071	42HP	1	Tip-up Handle	Ne
24576-072	63HP	1	Tip-up Handle	Ne

Katalogové číslo	Rack Width	Množství v balení	Typ rukojeti	Rychlé odeslání
24576-073	84HP	1	Tip-up Handle	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

To fit the tip-up carrying handle, holes must be drilled in the side panel.

Please select the preconfigured PropacPRO cases with holes for tip-up carrying handle.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE