


PSU Front Panel

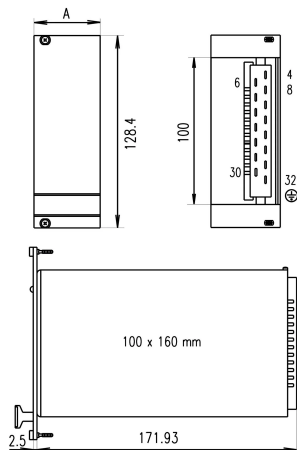

Front Panel for nVent SCHROFF 19" compatible Power Supply. Flat front panel with vertical grooves for stainless steel EMC Contact Strips.

CERTIFICATIONS



VLASTNOSTI

Front Panel, Al, Front anodized, rear conductive, with vertical Slots for EMC Contact Strips

SPECIFIKACE

Accessory Type: Front panel

Table 1/2

Katalogové číslo	Materiál	Front Finish	Rear Finish	Treated Edges	Rack Height	Výška
21006-959	Hliník	Anodized	Conductive	No	3U	128.4mm
21006-943	Hliník	Anodized	Conductive	No	3U	128.4mm

Katalogové číslo	Materiál	Front Finish	Rear Finish	Treated Edges	Rack Height	Výška
21006-955	Hliník	Anodized	Conductive	No	3U	128.4mm
21006-957	Hliník	Anodized	Conductive	No	3U	128.4mm
21006-954	Hliník	Anodized	Conductive	No	3U	128.4mm
21006-956	Hliník	Anodized	Conductive	No	3U	128.4mm
21005-476	Hliník	Anodized	Conductive	No	3U	128.4mm
21006-945	Hliník	Anodized	Conductive	No	3U	128.4mm
21005-475	Hliník	Anodized	Conductive	No	3U	128.4mm
31006-677	Hliník	Anodized	Conductive	No	3U	128.4mm
21005-470	Hliník	Anodized	Conductive	No	3U	128.4mm
21005-473	Hliník	Anodized	Conductive	No	3U	128.4mm
21005-477	Hliník	Anodized	Conductive	No	3U	128.4mm
21005-451	Hliník	Anodized	Conductive	No	3U	128.4mm
21005-474	Hliník	Anodized	Conductive	No	3U	128.4mm
21005-439	Hliník	Anodized	Conductive	No	3U	128.4mm
21005-478	Hliník	Anodized	Conductive	No	3U	128.4mm

Table 2/2

Katalogové číslo	Rack Width	Šířka	Hloubka	Množství v balení	Povrchová úprava	Rychlé odeslání
21006-959	3HP	14.9mm	2.5mm	1	Anodized	Ne

Katalogové číslo	Rack Width	Šířka	Hloubka	Množství v balení	Povrchová úprava	Rychléodeslání
21006-943	6HP	30.14mm	2.5mm	1	Anodized	Ne
21006-955	6HP	30.14mm	2.5mm	1	Anodized	Ne
21006-957	6HP	30.14mm	2.5mm	1	Anodized	Ne
21006-954	6HP	30.14mm	2.5mm	1	Anodized	Ne
21006-956	6HP	30.14mm	2.5mm	1	Anodized	Ne
21005-476	6HP	30.14mm	2.5mm	1	Anodized	Ne
21006-945	8HP	40.3mm	2.5mm	1	Anodized	Ne
21005-475	6HP	30.14mm	2.5mm	1	Anodized	Ne
31006-677	8HP	40.3mm	2.5mm	1	Anodized	Ne
21005-470	6HP	30.14mm	2.5mm	1	Anodized	Ne
21005-473	10HP	50.46mm	2.5mm	1	Anodized	Ne
21005-477	10HP	50.46mm	2.5mm	1	Anodized	Ne
21005-451	10HP	50.46mm	2.5mm	1	Anodized	Ne
21005-474	14HP	70.78mm	2.5mm	1	Anodized	Ne
21005-439	14HP	70.78mm	2.5mm	1	Anodized	Ne
21005-478	14HP	70.78mm	2.5mm	1	Anodized	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE