


Rear Panel for RatiopacPRO/PropacPRO, Perforated, Retrofit Shielding

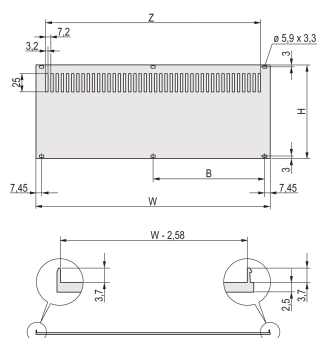

The perforated rear panel, Al, 2.5 mm is unshielded. The rear side is conductive.

CERTIFICATIONS



VLASTNOSTI

Rear panel, Al, 2.5 mm, front: anodized, rear: conductive; unshielded

Enables mounting on horizontal rails

SPECIFIKACE

Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Works With:	Cases
Produktová řada:	RatiopacPRO; RatiopacPRO AIR
Typ:	Rear Panel
Product Type:	Side Panel

Table 1/1

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Výška	Šířka	Rychlé odeslání
------------------	-------------	------------	-------------------	-------	-------	-----------------

20848-680	2U	42HP	1	83.5mm	213mm	Ne
20848-681	2U	63HP	1	83.5mm	319.7mm	Ne
20848-633	3U	28HP	1	123.4mm	141.9mm	Ne
20848-634	3U	42HP	1	123.4mm	213mm	Ne
20848-635	3U	63HP	1	123.4mm	319.7mm	Ne
20848-636	3U	84HP	1	123.4mm	426.4mm	Ne
20848-657	4U	42HP	1	168.9mm	213mm	Ne
20848-658	4U	63HP	1	168.9mm	319.7mm	Ne
20848-659	4U	84HP	1	168.9mm	426.4mm	Ne
20848-643	6U	84HP	1	256mm	426.4mm	Ne
20848-640	6U	28HP	1	256mm	141.9mm	Ne
20848-641	6U	42HP	1	256mm	213mm	Ne
20848-642	6U	63HP	1	256mm	319.7mm	Ne
20848-656	4U	28HP	1	168.9mm	141.9mm	Ne
20848-679	2U	28HP	1	83.5mm	141.9mm	Ne
20848-682	2U	84HP	1	83.5mm	426.4mm	Ne
20848-744	5U	28HP	1	220mm	141.9mm	Ne
20848-745	5U	42HP	1	220mm	213mm	Ne
20848-746	5U	63HP	1	220mm	319.7mm	Ne

20848-747	5U	84HP	1	220mm	426.4mm	Ne
-----------	----	------	---	-------	---------	----

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE