


Rear Panel for RatiopacPRO/PropacPRO, Perforated, Unshielded

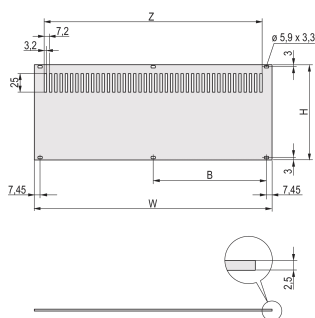

The perforated rear panel, Al, 2.5 mm is unshielded. The rear side is conductive.

CERTIFICATIONS



VLASTNOSTI

Rear panel, Al, 2.5 mm, front: anodized, rear: conductive; unshielded

Enables mounting on horizontal rails

For Mounting on Horizontal Rails

SPECIFIKACE

Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Works With:	Cases
Produktová řada:	RatiopacPRO; RatiopacPRO AIR
Typ:	Rear Panel
Product Type:	Side Panel

Table 1/1

Table 1/1						
Katalogové číslo	Rack Height	Rack Width	Množství v balení	Výška	Šířka	Rychlé odeslání

30849-007	2U	28HP	1	67.9mm	141.9mm	Ne
30849-014	2U	42HP	1	67.9mm	213mm	Ne
30849-008	3U	28HP	1	112.35mm	141.9mm	Ne
30849-015	2U	63HP	1	67.9mm	319.7mm	Ne
30849-009	4U	28HP	1	156.8mm	141.9mm	Ne
30849-021	3U	42HP	1	112.35mm	213mm	Ne
30849-028	4U	42HP	1	156.8mm	213mm	Ne
30849-011	5U	28HP	1	220mm	215mm	Ne
30849-016	2U	84HP	1	67.9mm	426.4mm	Ne
30849-035	6U	42HP	1	245.7mm	213mm	Ne
30849-010	6U	28HP	1	245.7mm	141.9mm	Ne
30849-022	3U	63HP	1	112.35mm	319.7mm	Ne
30849-171	5U	42HP	1	220mm	215mm	Ne
30849-023	3U	84HP	1	112.35mm	426.4mm	Ne
30849-029	4U	63HP	1	156.8mm	319.7mm	Ne
30849-172	5U	63HP	1	220mm	215mm	Ne
30849-030	4U	84HP	1	156.8mm	426.4mm	Ne
30849-036	6U	63HP	1	245.7mm	319.7mm	Ne
30849-173		84HP	1	220mm	215mm	Ne

30849-037	6U	84HP	1	245.7mm	426.4mm	Ne
-----------	----	------	---	---------	---------	----

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE