

Static Handle Plastic in Trapezoid Form, Grey



The static plastic handle, trapezoid form in grey color can be mounted to a front panel for extraction of the PCB.

CERTIFICATIONS



VLASTNOSTI

With separate identification plate, Al 1.5 mm

Handle, PC, UL 94 V-0

SPECIFIKACE

Works With:	Front Panels
Product Type:	Handle
Material:	Polyphenylene Ether
Typ:	Static

Table 1/2

Katalogové číslo	Rack Width	Množství v balení	Typ rukojeti	Flammability Rating	Barva	Kód barvy
20808-062	8HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-004	10HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-067	28HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-009	40HP	1	Trapezoid, Static	UL® 94V-0	Grey	
20808-068	42HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-012	61HP	1	Trapezoid, Static	UL® 94V-0	Grey	
20808-003	5HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-060	6HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-061	7HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-063	9HP	1	Trapezoid, Static	UL® 94V-0	Grey	
20808-064	12HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-065	14HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-066	21HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20809-294	3HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20809-295	4HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035

Table 2/2

Katalogové číslo	Complies With	Hloubka (D)	Výška (H)	Šířka (W)	Rychlé odeslání
20808-062	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	39.2mm	Ne


Katalogové číslo	Complies With	Hloubka (D)	Výška (H)	Šířka (W)	Rychlé odeslání
20808-004	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	49.4mm	Ne
20808-067	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	140.8mm	Ne
20808-009	EN 45545-2, R22-R24, HL3, IEC 60297-3-101			201.8mm	Ne
20808-068	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	212mm	Ne
20808-012	EN 45545-2, R22-R24, HL3, IEC 60297-3-101			308.5mm	Ne
20808-003	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	24mm	Ne
20808-060	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	29mm	Ne
20808-061	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	34.1mm	Ne
20808-063	EN 45545-2, R22-R24, HL3, IEC 60297-3-101			44.3mm	Ne
20808-064	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	59.6mm	Ne
20808-065	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	69.7mm	Ne
20808-066	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	105.2mm	Ne
20809-294	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	16.3mm	15.4mm	13.8mm	Ne
20809-295	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	16.3mm	15.4mm	18.9mm	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

Cannot be used together with fixing clip (21101-239).

DIAGRAMS

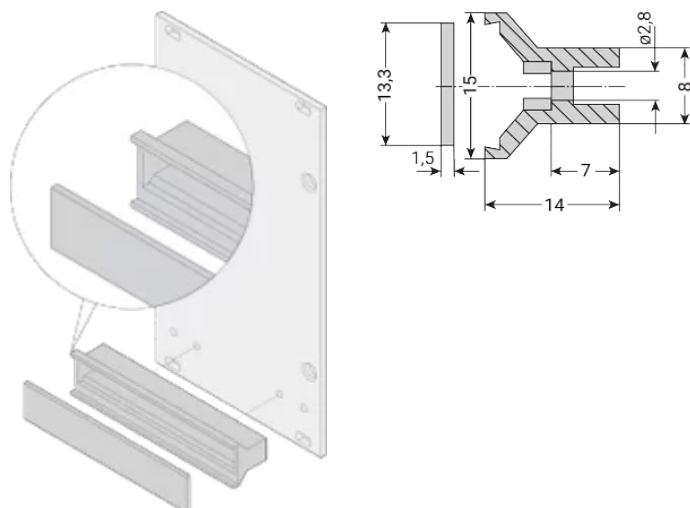

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE