


# Telescopic Slides C-Profile for Cabinet

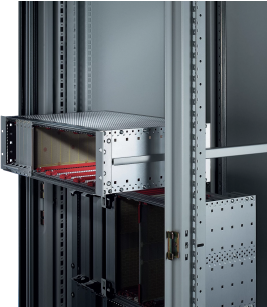

Telescopic slides with guiding profile for fitting in cabinets with 25 kg load capacity.

## CERTIFICATIONS



## VLASTNOSTI

For mounting 84 HP wide subracks in the 19" plane

Loading capacity: 25 kg per pair

The guiding profile (1) is matched to the fixing dimension in the cabinet (it is bolted to the 19" profile of the cabinet); the adaptor Rail (3) is matched to the depth and fixing dimension on the subrack (it is inserted into the guiding profile like a telescopic slide)

## SPECIFIKACE

<b>Materiál:</b>	Hliník
<b>Povrchová úprava:</b>	Anodized
<b>Typ:</b>	C Profile
<b>Product Type:</b>	Telescopic Slide

Table 1/1

Katalogové číslo	Hloubka	Množství v balení	Rychlé odeslání
24562-446	250mm	2	Ne

Katalogové číslo	Hloubka	Množství v balení	Rychlé odeslání
24562-460	500mm	2	Ne
24562-464	600mm	2	Ne
24562-449	600mm	2	Ne
24562-461	600mm	2	Ne
24562-466	800mm	2	Ne
24562-451	800mm	2	Ne
24562-474	800mm	2	Ne
24562-467	900mm	2	Ne
24562-452	900mm	2	Ne
24562-468	1000mm	2	Ne
24562-472	1100mm	2	Ne
24562-473	1200mm	2	Ne

## DALŠÍ PODROBNOSTI O PRODUKTU

No protection against extraction, no stop at full extension.

The reinforcement Rail and the C-Rails have been tested in accordance with the Russian atomic energy authority GAN standards.

## UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na [www.nvent.com](http://www.nvent.com) a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Naše portfolio silných značek:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**