


Test Adaptor for VMEbus

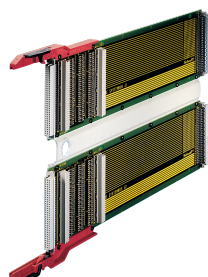

Test Adaptor for VMEbus Boards to access test points on the board.

CERTIFICATIONS



VLASTNOSTI

Routing and layer stack-up match the requirements of the VME bus

Measuring field for current and voltage measurement (V/I), (a)

Additional measuring pins, e.g. for the probe tips of an oscilloscope (b)

1 pin position for second test object, 1 pin position for terminator board

6 U test adaptors consist of two 3 U test adaptors linked via an intermediate adaptor

Voltage supply lines are designed for 2 A

SPECIFIKACE

Table 1/2

Katalogové číslo	Typ	Connector Type	Board Depth	Rack Height	Measuring Field	Number of Layers
23021-001	VMEbus	C96, System Bus	160mm	3U	Current, Voltage	6
23021-100	VMEbus	C96, I/O Bus	160mm	3U	Current, Voltage	6

Katalogové číslo	Typ	ConnectorType	Board Depth	Rack Height	MeasuringField	Number of Layers
23021-002	VMEbus	C96, System Bus	220mm	3U	Current, Voltage	6
23021-101	VMEbus	C96, I/O Bus	220mm	3U	Current, Voltage	6
23022-002	VMEbus	C96, System Bus, C96, I/O Bus	160mm	6U	Current, Voltage	6
23022-004	VMEbus	C96, System Bus, C96, I/O Bus	220mm	6U	Current, Voltage	6
23022-010	VMEbus	C96, System Bus, C96, I/O Bus	280mm	6U	Current, Voltage	6

Table 2/2

Katalogové číslo	Množství v balení	Rychlé odeslání
23021-001	1	Ne
23021-100	1	Ne
23021-002	1	Ne
23021-101	1	Ne
23022-002	1	Ne
23022-004	1	Ne
23022-010	1	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

For 9 U VMEbus test Adapter solution see Intermediate Adaptor Adaptor Bracket, 9 U, 220 mm, 350 mm.

P1 = System Bus, P2 = I/O Bus.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná

instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE