


U-profile Front Panel, Shieldable, D-Sub Cutouts

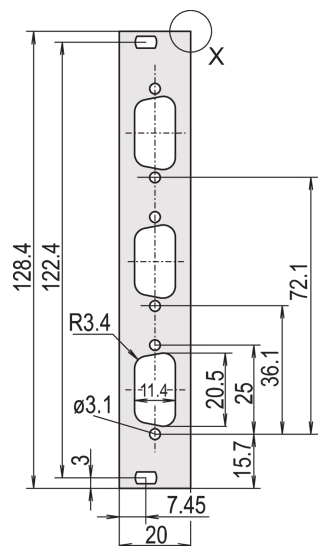

U-profile front panel with cutout for D-Sub connectors.
Shieldable for textile EMC gasket.

CERTIFICATIONS



VLASTNOSTI

U-profile, front panel, Al, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

SPECIFIKACE

Hloubka (D):	2.5mm
Rack Height:	3U
Rack Width:	4HP
Materiál:	Hliník
Povrchová úprava:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Typ:	Front Panel without Handle

EMC Shielding: No (Retrofittable)

Table 1/2

Katalogové číslo	Množství v balení	Mounting	Gasket Type	Front Finish	Rear Finish	Number of Pins
30849-751	1	Screw-on Front	Textile EMC	Anodized	Conductive	(3) 9
30849-750	1	Screw-on Front	Textile EMC	Anodized	Conductive	(2) 9
30849-752	1	Screw-on Front	Textile EMC	Anodized	Conductive	(1) 15
30849-754	1	Screw-on Front	Textile EMC	Anodized	Conductive	(1) 25
30849-753	1	Screw-on Front	Textile EMC	Anodized	Conductive	(2) 15
30849-755	1	Screw-on Front	Textile EMC	Anodized	Conductive	(2) 25
30849-749	1	Screw-on Front	Textile EMC	Anodized	Conductive	(1) 9

Table 2/2

Katalogové číslo	Treated Edges	Complies With	Výška (H)	Šířka (W)	Rychlé odeslání
30849-751	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Ne
30849-750	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Ne
30849-752	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Ne
30849-754	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Ne
30849-753	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Ne
30849-755	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Ne
30849-749	No	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Ne

DALŠÍ PODROBNOSTI O PRODUKTU


Please order fixing material (sleeves, collar screws) separately.


Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

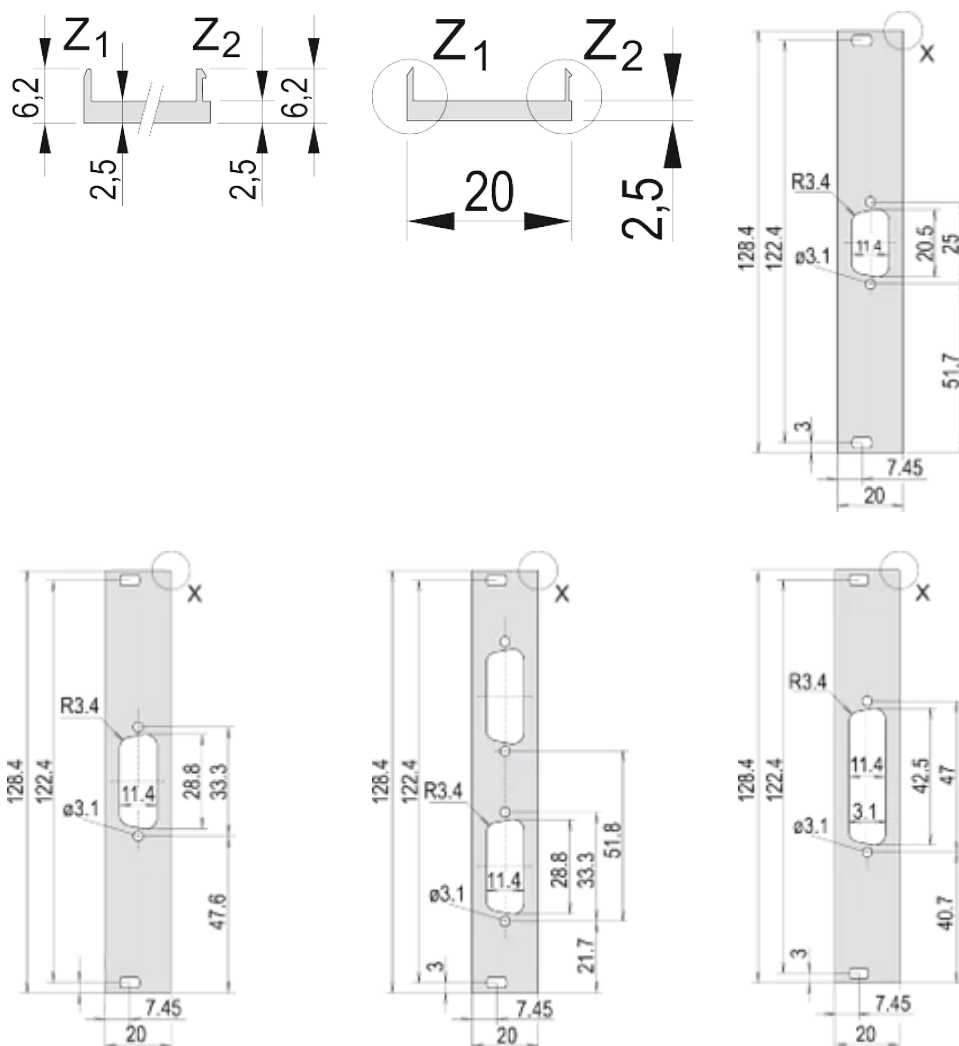

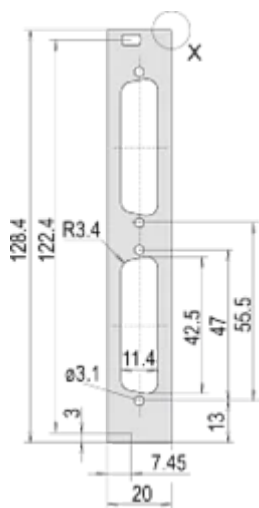

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE