


Varistar 19" Swing Frame Trim

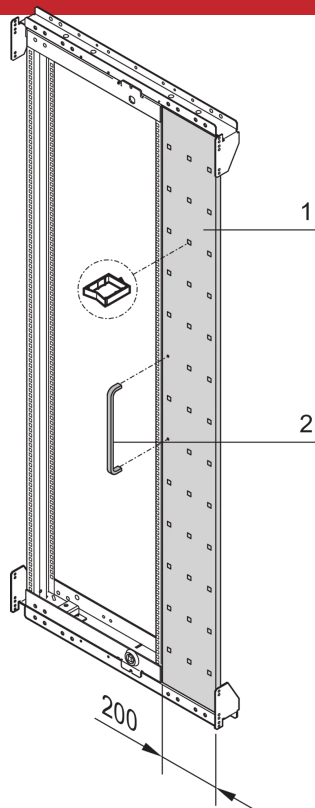

Varistar swing frame provides optimum space usage inside the rack. The swing frames come with handles.

CERTIFICATIONS



VLASTNOSTI

Includes handle and cut-out for cable eyes

To cover the gap between swing frame and cabinet upright for 800 mm wide cabinets

Max. swing bracket: 120 or 160

For swing frame with load-carrying capacity 150 kg, a stop is recommended for security reasons

Locking no. 333

Spare key for DIN semi-profile cylinder

SPECIFIKACE

Table 1/2

Katalogové číslo	Typ	Materiál	Frame Material	Barva	Kód barvy	Rack Height
21130-433	Swing	Ocel	Ocel	Black Grey	RAL 7021	29U
21130-437	Swing	Ocel	Ocel	Black Grey	RAL 7021	47U
21130-435	Swing	Ocel	Ocel	Black Grey	RAL 7021	38U
21130-447	Swing	Ocel	Ocel	Black Grey	RAL 7021	47U
21130-443	Swing	Ocel	Ocel	Black Grey	RAL 7021	29U
21130-445	Swing	Ocel	Ocel	Black Grey	RAL 7021	38U

Table 2/2

Katalogové číslo	Šířka	Works With	Povrchová úprava	Množství v balení	Rychlé odeslání
21130-433	800mm	Varistar CP	Strukturovaný Práškový	1	Ne
21130-437	800mm	Varistar CP	Strukturovaný Práškový	1	Ne
21130-435	800mm	Varistar CP	Strukturovaný Práškový	1	Ne
21130-447	800mm	Varistar CP	Strukturovaný Práškový	2	Ne
21130-443	800mm	Varistar CP	Strukturovaný Práškový	2	Ne
21130-445	800mm	Varistar CP	Strukturovaný Práškový	2	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE