


Varistar CP Mobile Frame

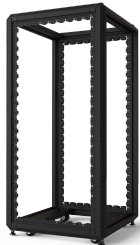

Varistar welded steel frame for static load requirements. For 19", ETSI or mounting plate integration. For mobile applications.

VLASTNOSTI

Welded, finish powder-coated, black gray, RAL 7021

SPECIFIKACE

Dynamic Load:	1000kg
Static Load:	1600kg
Product Type:	Cabinet/Rack Frame
Materiál:	Ocel

Table 1/2

Katalogové číslo	Rack Height	Výška	Šířka	Hloubka	Množství v balení	Barva
20630-252	52U	2450mm	600mm	1100mm	1	Black Grey
20630-255	52U	2450mm	800mm	1100mm	1	Black Grey
20630-231	42U	2000mm	600mm	1100mm	1	Black Grey
20630-232	42U	2000mm	600mm	1200mm	1	Black Grey
20630-237	42U	2000mm	800mm	1100mm	1	Black Grey
20630-238	42U	2000mm	800mm	1200mm	1	Black Grey

Katalogové číslo	Rack Height	Výška	Šířka	Hloubka	Množství v balení	Barva
20630-243	47U	2200mm	600mm	1100mm	1	Black Grey
20630-244	47U	2200mm	600mm	1200mm	1	Black Grey
20630-249	47U	2200mm	800mm	1100mm	1	Black Grey
20630-250	47U	2200mm	800mm	1200mm	1	Black Grey
20630-193	24U	1200mm	600mm	600mm	1	Black Grey
20630-194	24U	1200mm	600mm	800mm	1	Black Grey
20630-199	24U	1200mm	800mm	600mm	1	Black Grey
20630-200	24U	1200mm	800mm	800mm	1	Black Grey
20630-203	29U	1400mm	600mm	600mm	1	Black Grey
20630-204	29U	1400mm	600mm	800mm	1	Black Grey
20630-207	29U	1400mm	800mm	600mm	1	Black Grey
20630-208	29U	1400mm	800mm	800mm	1	Black Grey
20630-211	33U	1600mm	600mm	600mm	1	Black Grey
20630-212	33U	1600mm	600mm	800mm	1	Black Grey
20630-215	33U	1600mm	800mm	600mm	1	Black Grey
20630-216	33U	1600mm	800mm	800mm	1	Black Grey
20630-219	38U	1800mm	600mm	600mm	1	Black Grey
20630-220	38U	1800mm	600mm	800mm	1	Black Grey

Katalogové číslo	Rack Height	Výška	Šířka	Hloubka	Množství v balení	Barva
20630-223	38U	1800mm	800mm	600mm	1	Black Grey
20630-224	38U	1800mm	800mm	800mm	1	Black Grey
20630-227	42U	2000mm	600mm	600mm	1	Black Grey
20630-228	42U	2000mm	600mm	800mm	1	Black Grey
20630-229	42U	2000mm	600mm	900mm	1	Black Grey
20630-230	42U	2000mm	600mm	1000mm	1	Black Grey
20630-233	42U	2000mm	800mm	600mm	1	Black Grey
20630-234	42U	2000mm	800mm	800mm	1	Black Grey
20630-235	42U	2000mm	800mm	900mm	1	Black Grey
20630-236	42U	2000mm	800mm	1000mm	1	Black Grey
20630-239	47U	2200mm	600mm	600mm	1	Black Grey
20630-240	47U	2200mm	600mm	800mm	1	Black Grey
20630-241	47U	2200mm	600mm	900mm	1	Black Grey
20630-242	47U	2200mm	600mm	1000mm	1	Black Grey
20630-245	47U	2200mm	800mm	600mm	1	Black Grey
20630-246	47U	2200mm	800mm	800mm	1	Black Grey
20630-247	47U	2200mm	800mm	900mm	1	Black Grey
20630-248	47U	2200mm	800mm	1000mm	1	Black Grey

Katalogové číslo	Rack Height	Výška	Šířka	Hloubka	Množství v balení	Barva
20630-195	24U	1200mm	600mm	900mm	1	Black Grey
20630-196	24U	1200mm	600mm	1000mm	1	Black Grey
20630-201	24U	1200mm	800mm	900mm	1	Black Grey
20630-202	24U	1200mm	800mm	1000mm	1	Black Grey
20630-205	29U	1400mm	600mm	900mm	1	Black Grey
20630-206	29U	1400mm	600mm	1000mm	1	Black Grey
20630-209	29U	1400mm	800mm	900mm	1	Black Grey
20630-210	29U	1400mm	800mm	1000mm	1	Black Grey
20630-213	33U	1600mm	600mm	900mm	1	Black Grey
20630-214	33U	1600mm	600mm	1000mm	1	Black Grey
20630-217	33U	1600mm	800mm	900mm	1	Black Grey
20630-218	33U	1600mm	800mm	1000mm	1	Black Grey
20630-221	38U	1800mm	600mm	900mm	1	Black Grey
20630-222	38U	1800mm	600mm	1000mm	1	Black Grey
20630-225	38U	1800mm	800mm	900mm	1	Black Grey
20630-226	38U	1800mm	800mm	1000mm	1	Black Grey
20630-251	52U	2450mm	600mm	1000mm	1	Black Grey
20630-254	52U	2450mm	800mm	1000mm	1	Black Grey

Katalogové číslo	Rack Height	Výška	Šířka	Hloubka	Množství v balení	Barva
20630-253	52U	2450mm	600mm	1200mm	1	Black Grey
20630-256	52U	2450mm	800mm	1200mm	1	Black Grey

Table 2/2

Katalogové číslo	Kód barvy	Complies With	Frame Material	Typ	Works With	Rychlé odeslání
20630-252	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-255	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-231	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-232	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-237	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-238	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-243	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-244	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-249	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-250	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-193	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-194	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-199	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-200	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne

Katalogové číslo	Kód barvy	Complies With	Frame Material	Typ	Works With	Rychléodeslání
20630-203	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-204	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-207	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-208	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-211	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-212	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-215	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-216	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-219	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-220	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-223	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-224	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-227	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-228	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-229	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-230	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-233	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-234	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne

Katalogové číslo	Kód barvy	Complies With	Frame Material	Typ	Works With	Rychléodeslání
20630-235	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-236	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-239	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-240	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-241	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-242	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-245	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-246	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-247	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-248	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-195	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-196	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-201	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-202	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-205	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-206	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-209	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-210	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne

Katalogové číslo	Kód barvy	Complies With	Frame Material	Typ	Works With	Rychléodeslání
20630-213	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-214	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-217	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-218	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-221	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-222	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-225	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-226	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-251	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-254	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-253	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne
20630-256	RAL 7021	IEC 61587-1, IEC 61587-3	Ocel	Mobile	Varistar CP	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE