


Varistar CP Perforated, Seismic Base Plate, EMC, for Rear Cable Ducting

Varistar CP Base Plate for Rear Cable Ducting, plain for IP 55 or EMC applications.

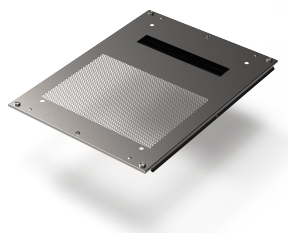

VLASTNOSTI

Installation from outside

Cutout at rear

60 mm deep

Cable ducting with IP 55 / EMC gasket

SPECIFIKACE

Product Type: Cabinet/Rack Base

Povrchová úprava: Hot-Dip Galvanized

Materiál: Ocel

Table 1/2

Katalogové číslo	Šířka	Hloubka	Množství v balení	Complies With	Typ	Works With
20630-327	600mm	1000mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP
20630-325	600mm	600mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP
20630-332	800mm	1200mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP

Katalogové číslo	Šířka	Hloubka	Množství v balení	Complies With	Typ	Works With
20630-331	800mm	1000mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP
20630-326	600mm	800mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP
20630-330	800mm	800mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP
20630-328	600mm	1200mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP
20630-329	800mm	600mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP

Table 2/2

Katalogové číslo	Rychlé odeslání
20630-327	Ne
20630-325	Ne
20630-332	Ne
20630-331	Ne
20630-326	Ne
20630-330	Ne
20630-328	Ne
20630-329	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Varistar CP Base Plate for Rear Cable Ducting, plain for IP 55 or EMC applications.

Please purchase the grounding kit separately.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE