


Varistar CP Seismic Base Plate, Multi-Piece

Multi piece base plate is assembled from inside.

Please order grounding, cover plate, brush strip or filter mat separately.

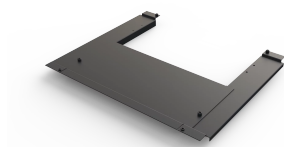

VLASTNOSTI

To cover the base opening

The multi-piece base plate is open at the rear (opening to rear 200 mm deep, no rear opening with 300 mm cabinet depth)

SPECIFIKACE

Product Type: Cabinet/Rack Base

Materiál: Ocel

Table 1/2

Katalogové číslo	Šířka	Hloubka	Množství v balení	Barva	Kód barvy	Complies With
20630-293	600mm	600mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2
20630-294	600mm	800mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2
20630-295	600mm	1000mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2
20630-296	600mm	1200mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2
20630-297	800mm	600mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2
20630-298	800mm	800mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2

Katalogové číslo	Šířka	Hloubka	Množství v balení	Barva	Kód barvy	Complies With
20630-299	800mm	1000mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2
20630-300	800mm	1200mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2

Table 2/2

Katalogové číslo	Povrchová úprava	Typ	Works With	Rychlé odeslání
20630-293	Strukturovaný Práškový	Base Plate, Plain	Varistar CP	Ne
20630-294	Strukturovaný Práškový	Base Plate, Plain	Varistar CP	Ne
20630-295	Strukturovaný Práškový	Base Plate, Plain	Varistar CP	Ne
20630-296	Strukturovaný Práškový	Base Plate, Plain	Varistar CP	Ne
20630-297	Strukturovaný Práškový	Base Plate, Plain	Varistar CP	Ne
20630-298	Strukturovaný Práškový	Base Plate, Plain	Varistar CP	Ne
20630-299	Strukturovaný Práškový	Base Plate, Plain	Varistar CP	Ne
20630-300	Strukturovaný Práškový	Base Plate, Plain	Varistar CP	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE