


Varistar Slide Rail

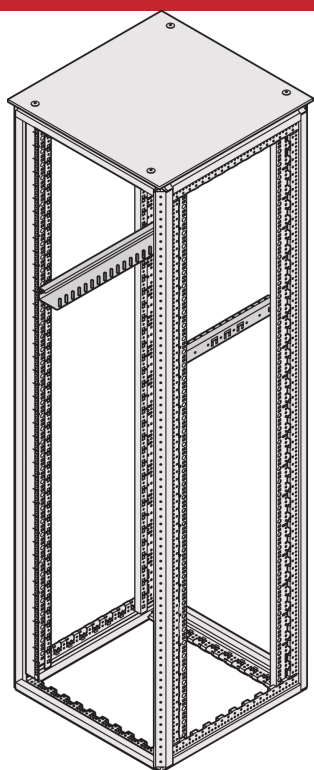

Mounts on four 19" slide mounts with 25/100 kg weight capacity.

CERTIFICATIONS



VLASTNOSTI

Mounts on four 19" slide mounts

Wide support surface (48 mm)

Can be fitted in 1 U increments (attach and screw into place)

SPECIFIKACE

Product Type: Slide Rail

Materiál: Ocel

Table 1/2

Katalogové číslo	Static Load	Množství v balení	Povrchová úprava	Výška	Length	Works With
23130-099		2	Aluminum-Zinc Plated			Varistar CP
23130-116	100kg	2	Aluminum-Zinc Plated	200mm	156mm	Varistar CP
23130-096	25kg	2	Aluminum-Zinc Plated	500mm	456mm	Varistar CP
23130-097	25kg	2	Aluminum-Zinc Plated	700mm	656mm	Varistar CP
23130-098	25kg	2	Aluminum-Zinc Plated	740mm	699mm	Varistar CP
23130-118	100kg	2	Aluminum-Zinc Plated	500mm	458mm	Varistar CP
23130-119	100kg	2	Aluminum-Zinc Plated	700mm	658mm	Varistar CP
23130-120	100kg	2	Aluminum-Zinc Plated	740mm	699mm	Varistar CP
23130-126		10	Aluminum-Zinc Plated			Varistar CP
23130-101	25kg	10	Aluminum-Zinc Plated	500mm	456mm	Varistar CP
23130-102	25kg	10	Aluminum-Zinc Plated	700mm	656mm	Varistar CP
23130-103	25kg	10	Aluminum-Zinc Plated	740mm	699mm	Varistar CP
23130-123	100kg	10	Aluminum-Zinc Plated	500mm	458mm	Varistar CP
23130-124	100kg	10	Aluminum-Zinc Plated	700mm	658mm	Varistar CP
23130-125	100kg	10	Aluminum-Zinc Plated	740mm	699mm	Varistar CP

Table 2/2

Katalogové číslo	Balení	Certifications	Rychlé odeslání
23130-099	Pair		Ne

Katalogové číslo	Balení	Certifications	Rychlé odeslání
23130-116		RoHS	Ne
23130-096	Pair	RoHS	Ne
23130-097	Pair	RoHS	Ne
23130-098	Pair	RoHS	Ne
23130-118		RoHS	Ne
23130-119		RoHS	Ne
23130-120		RoHS	Ne
23130-126		RoHS	Ne
23130-101		RoHS	Ne
23130-102		RoHS	Ne
23130-103		RoHS	Ne
23130-123		RoHS	Ne
23130-124		RoHS	Ne
23130-125		RoHS	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

For mounting in the cabinet the 19" panel/slide mounts must be fitted front and rear.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE