

310M Universal Beam Clamp, Thick Flange



CERTIFICERINGER



FUNKTIONER

Universal beam clamp for thick beams

SPECIFIKATIONER

Materiale: Cast Iron
Finish: Electrogalvanized

Table 1/2

Katalognummer	Artikelnummer	Hole Size (HS)	Hole Type	Flange Thickness (FT)	A	Torque (TQ)
310M12	388890	12 mm	Threaded	31.8 mm Max	28.6 mm	15 N·m
310M10	389890	10 mm	Threaded	31.8 mm Max	28.6 mm	7 N·m

Table 2/2


Katalognummer	Artikelnummer	Static Load 1 (F1)	Static Load 2 (F2)
---------------	---------------	--------------------	--------------------

310M12	388890	4200N	3300N
310M10	389890	2200N	1100N

YDERLIGERE PRODUKTOPLYSNINGER

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

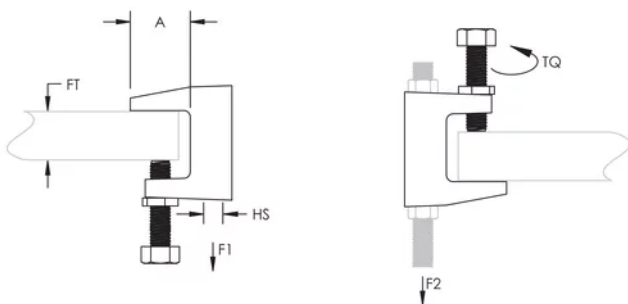

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

