

4G16 Twist Clip with Stud



CERTIFICERINGER



FUNKTIONER

Supports electrical fixtures from acoustical T-grid

No tools required for installation

Fast, easy and secure twist-on installation

Nut sold separately

SPECIFIKATIONER

Table 1/2


Katalognummer	Artikelnummer	Materiale	Finish	Farve	Flange Thickness (FT)	T-Grid Size
4G16M16	171900	Spring Stål, Stål	nVent CADDY Armour	Gray	1.5 mm	24mm
4G16M25	176880	Spring Stål, Stål	nVent CADDY Armour	Gray	1.5 mm	24mm
4G16M11	178600	Spring Stål, Stål	nVent CADDY Armour	Gray	1.5 mm	24mm

Katalognummer	Artikelnummer	Materiale	Finish	Farve	Flange Thickness (FT)	T-Grid Size
4G16M11WH	178620	Spring Stål, Stål	Painted	White	1.5 mm	24mm
4G16M7	178590	Spring Stål, Stål	nVent CADDY Armour	Gray	1.5 mm	24mm
4G16M16WH	576940	Spring Stål, Stål	Painted	White	1.5 mm	24mm

Table 2/2

Katalognummer	Artikelnummer	Screw Diameter (Sc)	Screw Length (L)	Static Load
4G16M16	171900	6	16mm	220N
4G16M25	176880	6	25mm	220N
4G16M11	178600	6	11mm	220N
4G16M11WH	178620	6	11mm	220N
4G16M7	178590	6	7mm	220N
4G16M16WH	576940	6	16mm	220N

DIAGRAMS

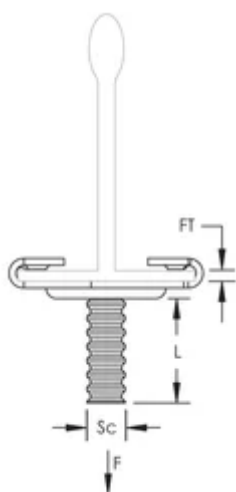

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug,

fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

