

4G24H Twist Clip with 90° Plain Hole



CERTIFICERINGER



FUNKTIONER

Provides an attachment for nVent CADDY Speed Link assemblies, wire, S-hooks, or chain from T-Grid

Fast, easy and secure twist-on installation

Designed to reduce scratching of T-grid

No tools required for installation

SPECIFIKATIONER

Materiale: Spring Steel

Table 1/2


Katalognummer	Artikelnummer	Finish	Farve	Hole Size (HS)	Flange Thickness (FT)	T-Grid Size
4G24H	170490	nVent CADDY Armour	Gray	5.8 mm	1.5 mm Max	24mm
4G24HWHSP25	172280	Painted	White	5.8 mm	1.5 mm Max	24mm

Katalognummer	Artikelnummer	Finish	Farve	Hole Size (HS)	Flange Thickness (FT)	T-Grid Size
4G24HWH	170500	Painted	White	5.8 mm	1.5 mm Max	24mm

Table 2/2

Katalognummer	Artikelnummer	Static Load
4G24H	170490	180N
4G24HWHSP25	172280	180N
4G24HWH	170500	180N

DIAGRAMS

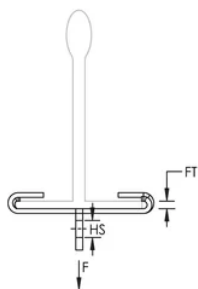

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte

