

ADK Strut End Cap



The nVent CADDY ADK Strut End Caps provide a safe and fast solution for handling sharp-edged strut channels. The ADK Caps are easily inserted into the ends of factory or field-cut strut channels and help prevent potential injuries caused by rough edges found on material ends. Additionally, this simple solution works with multiple strut channel profile types and is available in several different colors to suit individual applications.

FUNKTIONER

Fits into ERISTRUT Type A, B, C and D strut channel, both slotted and solid

When separated, provides two end caps for ERISTRUT Type C channel

SPECIFIKATIONER

Materiale: Polyethylen

Table 1/2


Katalognummer	Artikelnummer	Farve	Strut Type	Height (H)	Width (W)	A
ADK421	313305	Blue	A (41 x 41 mm), C (21 x 41 mm)	41.2 mm	41.2 mm	20.6 mm
ADK421GY	313308	Gray	A (41 x 41 mm), C (21 x 41 mm)	41.2 mm	41.2 mm	20.6 mm

Table 2/2

Katalognummer	Artikelnummer	B	Thickness (T)
ADK421	313305	8.5 mm	11.5 mm

Katalognummer	Artikelnummer	B	Thickness (T)
ADK421GY	313308	8.5 mm	11.5 mm

DIAGRAMS

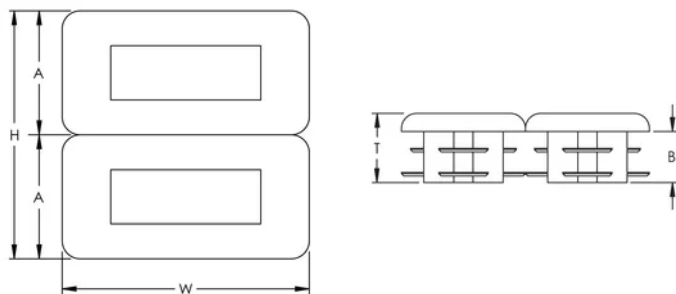

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

